
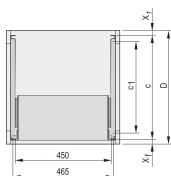


# Teleskopiske lysbilder C-profil for kabinett for montering av Novastar, 800 mm

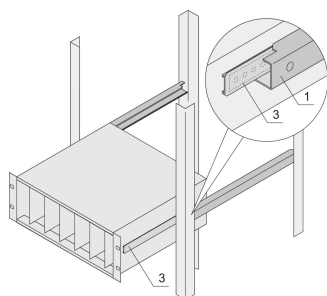

## KATALOGNUMMER

**24562-474**

Teleskopiske rutsjebaner med styreprofil for montering i skap med 25 kg lastekapasitet.

## FUNKSJONER

For montering av 84 hk brede subracks i 19-tommers planet

Lastekapasitet: 25 kg per par.

Styringsprofilen (1) er tilpasset festedimensjonen i skapet (den er boltet til skapsprofilen på 19 tommer);  
adapterskinne (3) er tilpasset dybde- og festedimensjonen på underholderen (den settes inn i styringsprofilen som en teleskopisk skyvebryter)



## PRODUKTEGENSKAPER

Produktserie: Novastar

Dybde: 800mm

Antall pakker: 2

Overflate: Anodisert

Materiale: Aluminium

Produkttype: Uttrekkbar skinne

Type: C-profil

Nettovekt: 0.66kg

\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## YTTERLIGERE PRODUKTDETALJER

Ingen beskyttelse mot ekstraksjon, ingen stopp ved full forlengelse.

Armeringsjernbanen og C-Rails er testet i henhold til den russiske atomenergimyndigheten GAN standarder.

## ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell.

Instruksjonsark er tilgjengelig på [www.nvent.com](http://www.nvent.com) og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vår solide portefølje av merkevarer:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**