

# Kombinert monteringssett for chassis, 84:0 HP

## KATALOGNUMMER


**24562-484**

Den kombinerte monteringen gjør det mulig å dele en 6 U høy subrack eller koffert i 2 x 3 U og 6 U seksjoner. Forskjellige versjoner er tilgjengelige.

## FUNKSJONER

Designet for å akseptere Euroboards (100 mm høy) og Euroboards (233,35 mm høy)

Oppdeling av monteringsområdet 6 U i: 2 x 3 U, 1 x 6 U

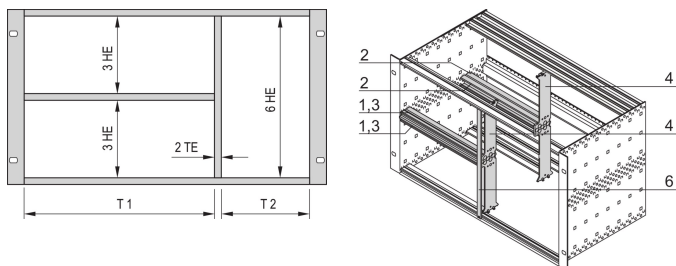

## PRODUKTEGENSKAPER

Antall pakker: 1

Rackbredde 1: 84HP

Materiale: Aluminium; Sinklegering

Produktserie: EuropacPRO

Produkttype: Monteringssett

Rackhøyde: 6U

Type: Kombinert

Fungerer med: Delrack

Nettovekt: 0.657kg

\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## YTTERLIGERE PRODUKTDETALJER

Vennligst bestill separat: Frontpanel 6 U, 2 HP for å dekke til staget.

Følgende styreskiner kan ikke brukes: Type tilbehør, type tilbehør, forsterket og type for 4,4 PCB.

## ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på [www.nvent.com](http://www.nvent.com) og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vår solide portefølje av merkevarer:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**