

EuropacPRO 19-tommers Subrack Kit for bakplan, tung, Retrofit skjerming, med fronthåndtak, 6 U, 355 mm

KATALOGNUMMER

24567-464

Ikke-EMC skjermet subrack for bakplanmontering, tung versjon med tox-sveisede sidepaneler og fronthåndtak.

FUNKSJONER

Subrack med sidepanel type H («tung»), 19-tommers brakett er fast festet til sidepanelet (tox-kald sveiset)

Leveres som plassbesparende flatpakke

Bakre horizontal skinne for montering i bakplan med isolasjonsbånd

Horizontal skinnetype «tung»

Støt- og vibrasjonsmotstand opptil 5 g.


IP 20, i samsvar med IEC 60529

Støt og vibrasjon testet i henhold til de tyske standardene BN 411002, BN 411003

Interne og eksterne dimensjoner i henhold til: IEC 60297-3-100, -101, IEEE 1101,1

Installert last opp til 15 kg.

Versjon med fronthåndtak

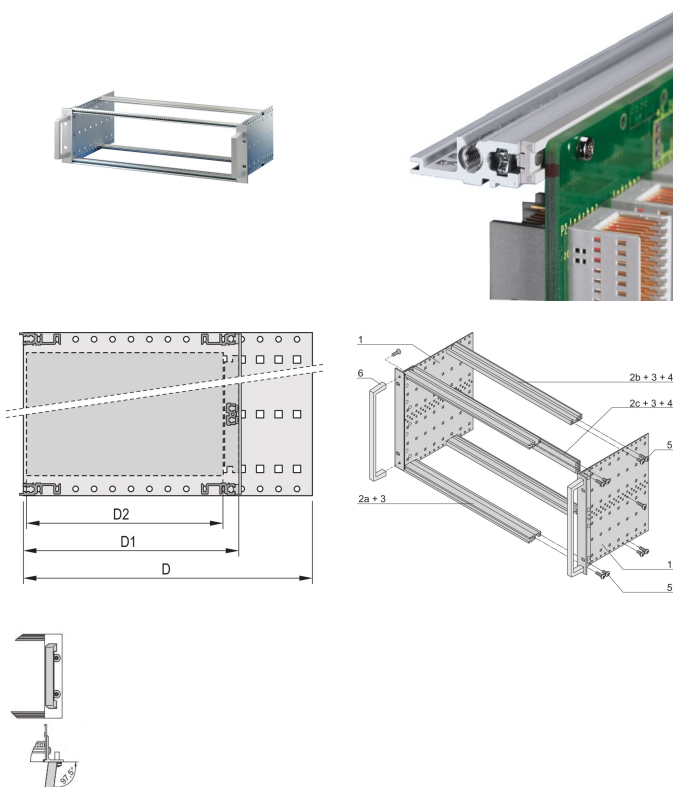

PRODUKTEGENSKAPER

Rackhøyde: 6U

Dybde: 355mm

Antall pakker: 1

For montering: Sentralenhet

Kortdybde: 160mm; 220mm; 280mm; 340mm



Pakning: Rustfritt stål EMC

Støt- og vibrasjonstoleranse: 5g (force)

Håndtak inkludert: Ja

Montering: Stativ

Samsvarer med: IEC 60297-3-103

EMC-beskyttelse: Nei

Overflate: Anodisert; Passivert

Materiale: Aluminium

Produkttype: Delrack/chassis

Rackbredde: 84HP

Statisk belastning: 15kg

Nettvekt: 2.5kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Individuell konfigurasjon: Bredt utvalg av varianter i høyde, bredde og dybde; føringskinner for et bredt spekter av applikasjoner; innvendige alternativer; tilbehør og monteringsmateriale.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmaterieil. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE