

RatiopacPRO EMC frontpanel, spant, skjermet, 3 U, 42 HP, 2,5 mm, Al, front anodisert, bakre ledende

KATALOGNUMMER


24572-604

EMC-frontpanelet kan settes inn i spesielle horisontale skinner med en høyde. Det er ikke nødvendig med skruer for å feste. Designet gjør det mulig for brukere å bruke en frontfolie.

FUNKSJONER

Feste krever ikke skruer

Spesielle horisontale skinner dekker kantene på frontpanelet (øverst og nederst), og forhindrer at frontpanelet bøyer seg

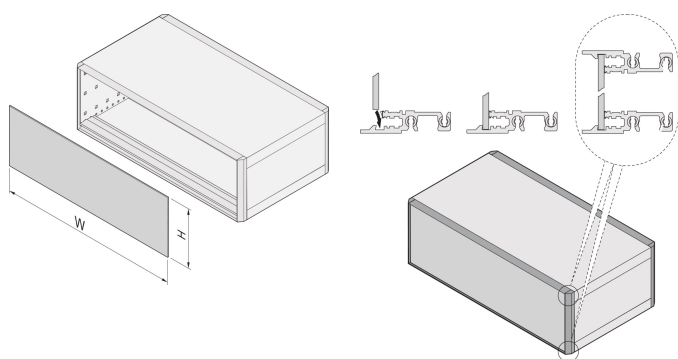

PRODUKTEGENSKAPER

Rackhøyde: 3U

Rackbredde: 42HP

Tilbehørstype: Frontpanel

Antall pakker: 1

Fremre overflate: Anodisert

Bakre flate: Strømledende

Behandlede kanter: Nei

Dybde: 2.5mm

Overflate: Anodisert; Passivert

Høyde: 128.4mm

Materiale: Aluminium

Produkttype: Frontpanel

Bredde: 213.2mm

Nettovekt: 0.55kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

For å oppnå en skjermet kasse må alle EMC-forseglinger monteres (frontpanel/bakpanel? Sidepanel, sidepanel? Dekselplate, frontpanel/bakpanel – horisontal skinne, horisontal skinne – horisontal skinne).

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE