


Frontpanel alternativ for kombinert montering, U-profil, tekstil, 6 U, 2 HP, 2,5 mm, Al, front anodisert, bakre ledende

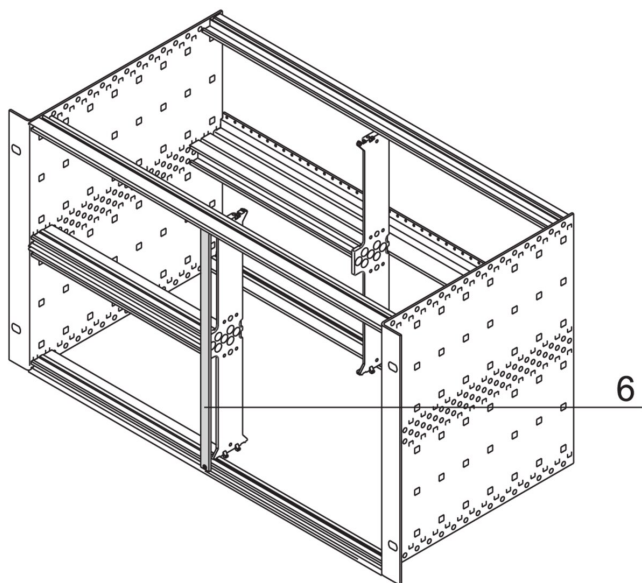

KATALOGNUMMER

30849-140

Det brede frontpanelet på 2 hk dekker et åpent spor. U-profilfrontpanelet kan kombineres med en EMC-pakning av tekstil. Den festes med skruer og skiver. På grunn av bredden på 2 hk kan ingen hylser brukes.

FUNKSJONER

U-profil frontpanel 6 U, 2 HP, Al, 2,5 mm.

Forberedt for tekstil EMC-pakning



PRODUKTEGENSKAPER

Produkttype: Frontpanel

Tilbehørstype: Frontpanel

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; CompacPRO; PropacPRO

Montering: Front som skrus på

EMC-beskyttelse: Nei (kan monteres etterpå)

Pakning: Tekstil

Materiale: Aluminium

Fremre overflate: Anodisert

Bakre flate: Strømledende

Behandlede kanter: Nei

Rackhøyde: 6U

Høyde: 261.8mm

Rackbredde: 2HP

Bredde: 9.8mm

Dybde: 2.5mm

Samsvarer med: IEC 60297-3-101; IEEE 1101,1/10

Antall pakker: 1

Overflate: Anodisert; Passivert

Nettovekt: 0.021kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Vær oppmerksom på at leveranser kan utføres i de angitte SPQ (SPQ, f.eks. 5 stk, 10 stk, 50 stk, etc.). Ulike ordreantall (f.eks. 2 stk) kan endres til neste mulige leveringsantall = Standard pakkeantall.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE