


Vannrett skinne, front, type H-LD, tung, lang leppe, for IEEE-applikasjon, 1000 mm

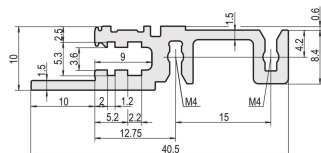

KATALOGNUMMER

34560-301

Den horisontale skinnen med lang leppe muliggjør bruk av IEEE innsetting/ekstraksjonshåndtak.

FUNKSJONER

For plug-in-enheter med IEEE-håndtak

Lang leppe (H-LD)

Installasjon øverst og nederst

For CPCI- og VME64x-systemer

Aluminiumsekstrudering, anodisert finish, ledende kontaktoverflate

Combinations of horizontal rails and side panels

	IEEE 1000mm	IEEE 500mm	IEEE 250mm	IEEE 125mm
IEEE 1000mm	+	+	+	+
IEEE 500mm	+	+	+	+
IEEE 250mm	+	+	+	+
IEEE 125mm	+	+	+	+



PRODUKTEGENSKAPER

Rackbredde: 195HP

Antall pakker: 1

Overflate: Anodisert

Lengde: 1000mm

Materiale: Aluminium

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; CompacPRO; PropacPRO

Produkttype: Horisontal skinne

Type: Tungt, LD

Fungerer med: Delrack; Esker

Nettovekt: 0.389kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Levering er i standard pakke multipler. Prisen er per enkelt element.

Vær oppmerksom på at leveranser kan utføres i de angitte SPQ (SPQ, f.eks. 5 stk, 10 stk, 50 stk, etc.). Ulike ordreantall (f.eks. 2 stk) kan endres til neste mulige leveringsantall = Standard pakkeantall.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE