


# Vannrett skinne, front, type H-LD, tung, lang leppe, for IEEE-applikasjon, 28 HP

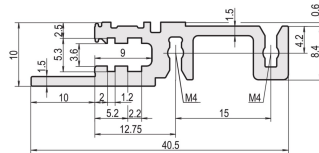

## KATALOGNUMMER

**34560-328**

Den horisontale skinnen med lang leppe muliggjør bruk av IEEE innsetting/ekstraksjonshåndtak.

## FUNKSJONER

For plug-in-enheter med IEEE-håndtak

Lang leppe (H-LD)

Installasjon øverst og nederst

For CPCI- og VME64x-systemer

Aluminiumsekstrudering, anodisert finish, ledende kontaktoverflate

Combinations of horizontal rails and side panels

|           | IEEE 1000 | IEEE 1000 | IEEE 1000 | IEEE 1000 |
|-----------|-----------|-----------|-----------|-----------|
| IEEE 1000 | +         | +         | +         | +         |
| IEEE 1000 | +         | +         | +         | +         |
| IEEE 1000 | +         | +         | +         | +         |
| IEEE 1000 | +         | +         | +         | +         |



## PRODUKTEGENSKAPER

Rackbredde: 28HP

Antall pakker: 1

Overflate: Anodisert

Lengde: 147.32mm

Materiale: Aluminium

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; CompacPRO; PropacPRO

Produkttype: Horisontal skinne

Type: Tungt, LD

Fungerer med: Delrack; Esker

\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## YTTERLIGERE PRODUKTDETALJER

Levering er i standard pakke multipler. Prisen er per enkelt element.

Vær oppmerksom på at leveranser kan utføres i de angitte SPQ (SPQ, f.eks. 5 stk, 10 stk, 50 stk, etc.). Ulike ordreantall (f.eks. 2 stk) kan endres til neste mulige leveringsantall = Standard pakkeantall.

## ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på [www.nvent.com](http://www.nvent.com) og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vår solide portefølje av merkevarer:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**