
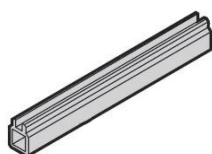
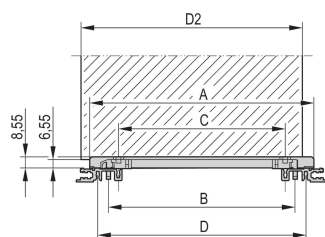


Guide Rail Multi Piece, Mid-Piece, Aluminum ekstrudering, 340 mm, 2 mm Groove bredde, 10 stykker

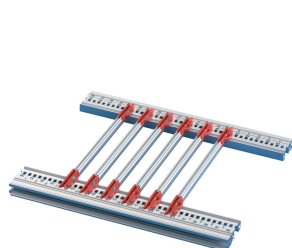

KATALOGNUMMER

34560-894

Styreskinne midtstykke for individuelle styreskinner i flere deler ut av plast eller aluminiumsekstrudering. Passer for standard, Accessory, 4,4-tommers PCB-typer og endestykker med koding.

FUNKSJONER

Midtprofil for montering av føringsskinner for 2 mm sporvidde

2 plast endestykker er nødvendig; disse er presset på til begge ender av midtprofilen

Styreskinner kan klippes inn i horisontale skinner (Al ekstrudering) eller i 1,5 mm tykke plater

Lagringstemperatur: Fra -40 °C 130 °C



PRODUKTEGENSKAPER

Produkttype: Styreskinne

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; CompacPRO; PropacPRO; MultipacPRO; Inpac

Type: Midtre del

Fungerer med: Delrack; Esker; Chassis

Kortdybde: 340mm

Rillebredde: 2

Materiale: Aluminium

Farge: Sølv

Antall pakker: 1

Overflate: Anodisert

Nettovekt: 0.017kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

leveringspakke være i Standard pakkeantall (SPQ). Prisen er per enkelt element.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE