


Vannrett skinne bak, type AB for bakre i/O-styreskinner, 40 hk

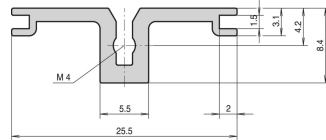

Combinations of horizontal rails and side panels

	Side panel not installed	Side panel installed	Side panel installed (not recommended)	Side panel installed (not recommended)
Horizontal rail	+	+	+	+
Vertical rail	+	+	+	+
Horizontal rail	+	+	+	+
Vertical rail	+	+	+	+

KATALOGNUMMER

34561-540

Aluminium ekstrudering horisontal skinne av typen AB (AB = støtte), for bakre i/O-kortføringer, med en anodisert overflate og ledende kontaktoverflate. Egnet for RatiopacPRO/-AIR og EuropacPRO/-robust).

FUNKSJONER

For CompactPCI i området bak i/O

For 2 x 3 U-utvidelse kreves 2 horisontale skinner av type AB

Aluminiumsekstrudering, anodisert overflate, ledende kontaktoverflate, uten HP-merking



PRODUKTEGENSKAPER

Rackbredde: 40HP

Antall pakker: 1

Overflate: Anodisert

Lengde: 208.28mm

Materiale: Aluminium

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; CompacPRO; PropacPRO

Produkttype: Horisontal skinne

Type: Type AB

Fungerer med: Delrack; Esker

Bruttovekt: 0.035kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Levering er i standard pakke multipler. Prisen er per enkelt element.

Vær oppmerksom på at leveranser kan utføres i de angitte SPQ (SPQ, f.eks. 5 stk, 10 stk, 50 stk, etc.). Ulike ordreantall (f.eks. 2 stk) kan endres til neste mulige leveringsantall = Standard pakkeantall.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE