

Monteringsplate for 19-tommers veske og Subrack, 63 HP, 160 mm Brettlengthe

KATALOGNUMMER

34562-747

Monteringsplate for tunge komponenter eller proprietære elektroniske enheter. Egnert for RatiopacPRO/-AIR, CompacPRO og EuropacPRO.

Styreskinner type 4,4 og forsterket type kan ikke brukes i kombinasjon med en monteringsplate. Topp-/bunndeksel som settes inn i sporet på lykten (type L) horisontale skinner, kan ikke brukes i kombinasjon med en monteringsplate.


FUNKSJONER

For montering av tunge komponenter

Monteringsplate, full bredde: Monteringsplaten er like bred som dekselet/systemdekselet og er festet til sidepanelene

Monteringsplate, delvis bredde: Monteringsplaten med delvis bredde er festet til sidepanelet ved hjelp av en monteringsstripe

Chassisplaten kan ikke kombineres med EMC topp-
/bunndeksler

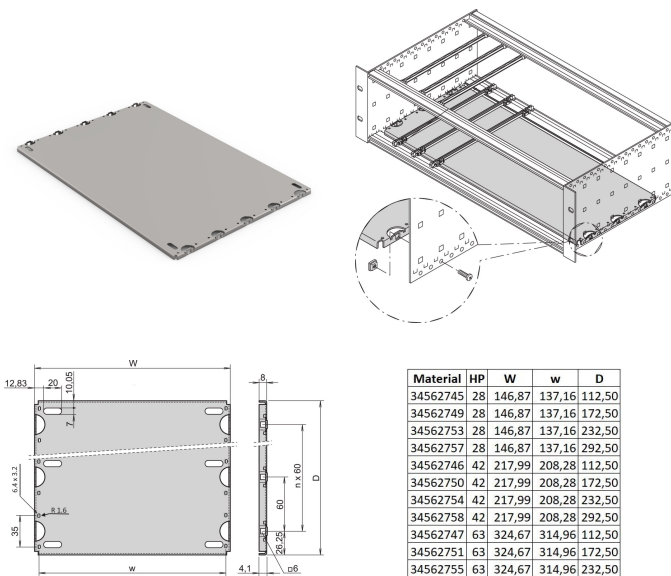

Material	HP	W	w	D
34562745	28	146,87	137,16	112,50
34562749	28	146,87	137,16	172,50
34562753	28	146,87	137,16	232,50
34562757	28	146,87	137,16	292,50
34562746	42	217,99	208,28	112,50
34562750	42	217,99	208,28	172,50
34562754	42	217,99	208,28	232,50
34562758	42	217,99	208,28	292,50
34562747	63	324,67	314,96	112,50
34562751	63	324,67	314,96	172,50
34562755	63	324,67	314,96	232,50
34562759	63	324,67	314,96	292,50
34562748	84	431,35	421,64	112,50
34562752	84	431,35	421,64	172,50
34562756	84	431,35	421,64	232,50
34562760	84	431,35	421,64	292,50
34562870	84	431,35	421,64	352,50
34562871	84	431,35	421,64	412,50

PRODUKTEGENSKAPER

Rackbredde: 63HP

Antall pakker: 1

Dybde: 112.5mm

Materiale: Aluminium

Produktserie: EuropacPRO; PropacPRO; RatiopacPRO; CompacPRO

Produkttype: Monteringsplate

Bredde: 324.67mm

Fungerer med: Delrack

Nettovekt: 0.18kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Bestill monteringssett for monteringsplate separat.

Andre versjoner på forespørsel.

Festestrimler som kreves for delvis bredde, vennligst bestill separat.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE