

Tilbehør for tunge PCB, ekstra sterk, aluminium, 280 mm, 2 mm Groove bredde, sølv

KATALOGNUMMER

34562-883


Denne forsterkede styreskinne for tung PCB av typen tilbehør danner et pålitelig grensesnitt mellom underhekkmekanikken og underenhetene. Styreskinnene kan i tillegg boltes til horisontalplanet

FUNKSJONER

For spesielt tunge PCB-er, plug-in-enheter eller ramme type plug-in-enheter

Montering, kun for bolting etter type H (tung) og type R (robuste) horisontale skinner

Aluminiumsprofil

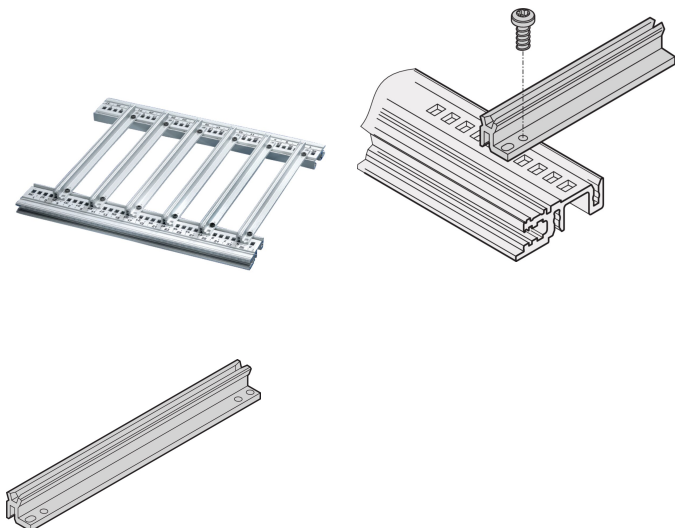

PRODUKTEGENSKAPER

Antall pakker: 1

Kortdybde: 280mm

Rillebredde: 2

Farge: Sølv

Overflate: Anodisert

Materiale: Aluminium

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; CompacPRO; PropacPRO; MultipacPRO; Inpac

Produkttype: Styreskinne

Type: Kraftig

Fungerer med: Delrack; Esker; Chassis

Bruttovekt: 0.025kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products

may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Levering er utelukkende i standard pakkeantall.

Vær oppmerksom på at leveranser kan utføres i de angitte SPQ (SPQ, f.eks. 5 stk, 10 stk, 50 stk, etc.). Ulike ordreantall (f.eks. 2 stk) kan endres til neste mulige leveringsantall = Standard pakkeantall.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE