

EuropacPRO monteringsplate for bruk med dekselplate, 42 hk, 160 mm Brettlengthe

KATALOGNUMMER

34563-002

Monteringsplate for bruk med dekselplater for montering og festing av tunge komponenter. Monteringsplater i full bredde (like bred som bæreplaten eller systemdekselet) er festet til sidepanelene. Monteringsplatene med delvis bredde er festet til sidepanelet og den horisontale skinnen ved hjelp av en monteringsstripe.

Styreskiner type 4,4 og forsterket type kan ikke brukes i kombinasjon med en monteringsplate. Topp-/bunndeksel som settes inn i sporet på lykten (type L) horisontale skinner, kan ikke brukes i kombinasjon med en monteringsplate.

FUNKSJONER


For montering og festing av tunge komponenter

Monteringsplate, full bredde: Monteringsplaten er like bred som dekselet/systemdekselet og er festet til sidepanelene

En styreskinne kan monteres i første og siste sporstilling

I tillegg til monteringsplaten kan EMC-dekselplater også monteres på underplaten

Styreskiner type 4,4 og forsterket kan ikke brukes

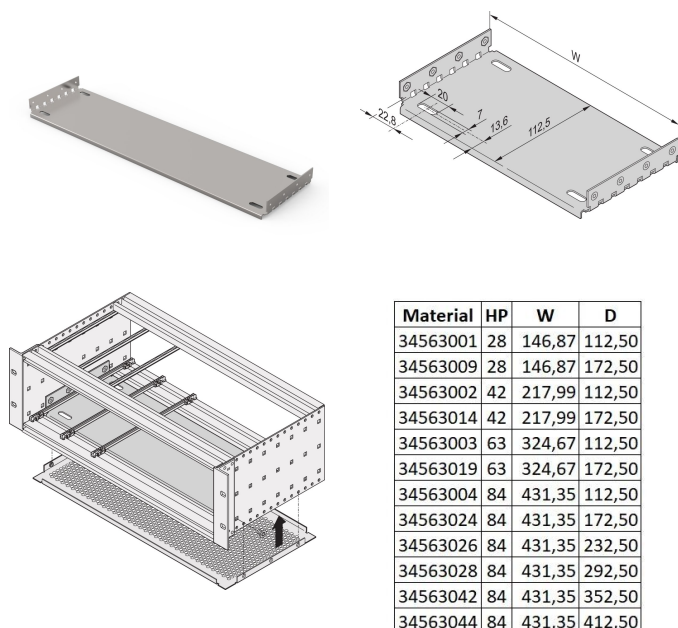

Material	HP	W	D
34563001	28	146,87	112,50
34563009	28	146,87	172,50
34563002	42	217,99	112,50
34563014	42	217,99	172,50
34563003	63	324,67	112,50
34563019	63	324,67	172,50
34563004	84	431,35	112,50
34563024	84	431,35	172,50
34563026	84	431,35	232,50
34563028	84	431,35	292,50
34563042	84	431,35	352,50
34563044	84	431,35	412,50

PRODUKTEGENSKAPER

Rackbredde: 42HP

Antall pakker: 1

Dybde: 112.5mm

Materiale: Aluminium

Produktserie: EuropacPRO

Produkttype: Monteringsplate

Bredde: 217.99mm

Fungerer med: Delrack

Nettovekt: 0.125kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE