


Styreskinne endestykke, Standard type, Groove bredde 2 mm, rød

Obsolete

KATALOGNUMMER

64560-004

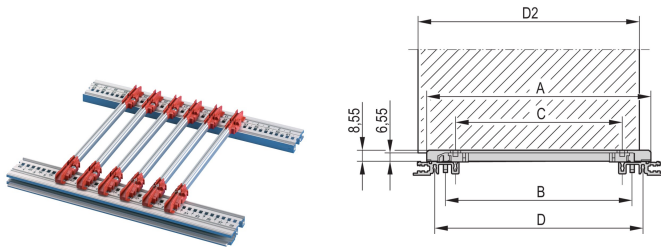

Plast endestykker for individuelle flerdelte føringskinner med plast eller ekstrudering midtstykke. Tilgjengelig som standard-, Accessory- eller 4,4-tommers PCB-typer. Endestykker kan være valgfritt utstyrt med en ESD-klemme, som sikrer ledende kontakt mellom PCB og horisontal skinne. Egnet for RatiopacPRO/-AIR, PropacPRO, CompacPRO og EuropacPRO.

FUNKSJONER

Styreskinnesluttstykker (PBT) for individuelle styreskinner i flere deler med plast- eller aluminiumsekstrudering.

Styreskinner endestykke kan klippes inn i horisontale skinner (Al ekstrudering) eller i 1,5 mm tykke plater

Lagringstemperatur: 0 °C ... +60 °C



PRODUKTEGENSKAPER

Produkttype: Skinneendestykke

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; CompacPRO; PropacPRO; MultipacPRO; Inpac

Type: Standard

Fungerer med: Delrack; Esker; Chassis

Antall pakker: 1

Pakkeenhet: Par

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Levering er i standard pakke multipler. Prisen er per enkelt element.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE