


Standard type, med din Connector feste, plast, 220 mm, 2 mm Groove bredde, rød, 1 par

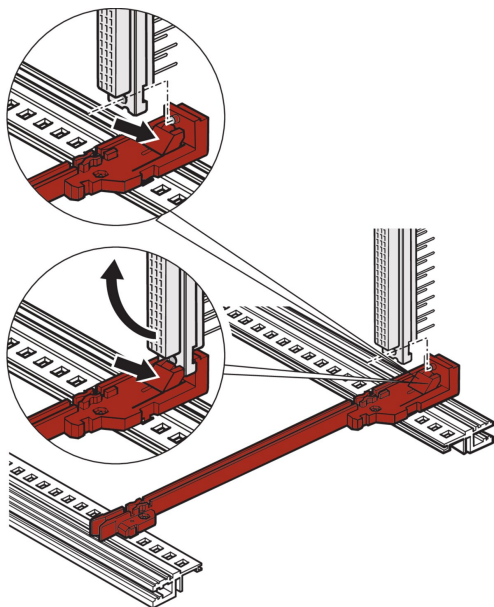

KATALOGNUMMER

64560-075

Standard styreskinne med koblingsfeste gjør det mulig for brukeren å klemme din-kontaktene (en 60603-2 (din 41612) direkte på føringsskinnene. Kan bare brukes med Euroboards med dimensjonene 100 x 160 mm og 100 x 220 mm. egnet for RatiopacPRO/-AIR, PropacPRO, CompacPRO og EuropacPRO.

FUNKSJONER

Enkel og økonomisk montering av kontakter gjennom snap tilkoblinger som alternativ til z-skinner eller horisontale skinner med integrert z-skinne

For ett Euroboard-format 100 x 160 mm eller 100 x 220 mm; ikke egnet for dobbelt Euroboard-format

Plastføringsskinne, ett stykke, rød, for sporvidde på 2 mm.

Kan klippes inn i horisontale skinner i Al ekstrudering

Kan klippes til 1,5 mm tykk plate

Lagringstemperatur: Fra -40 °C 130 °C



PRODUKTEGENSKAPER

Antall pakker: 2

Kortdybde: 220mm

Rillebredde: 2

Farge: Rød

Samsvarer med: EN 60603-2 (DIN 41612)

Materiale: Polybutylentereftalat

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO Air; CompacPRO; PropacPRO; MultipacPRO; Inpac

Produkttype: Styreskinne

Type: Standard med DIN-kontakt

Fungerer med: Delrack; Esker; Chassis

Pakkeenhet: Par

Nettovekt: 0.026kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGERE PRODUKTDETALJER

Levering er i standard pakke multipler. Prisen er per enkelt element.

Vær oppmerksom på at leveranser kan utføres i de angitte SPQ (SPQ, f.eks. 5 stk, 10 stk, 50 stk, etc.). Ulike ordreantall (f.eks. 2 stk) kan endres til neste mulige leveringsantall = Standard pakkeantall.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmaterieil. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE