

Przegroda powietrzna, panel przedni U, osłona przebudowy, tekstylna, 6 U, 8 HP, 160 mm

Obsolete

NUMER KATALOGOWY


20848-738

Przegroda powietrza z przednim panelem w kształcie litery U zakrywa puste gniazdo, aby wyeliminować przepływ powietrza. Przedni panel w kształcie litery U akceptuje tekstylną uszczelkę EMC.

FUNKCJE

przegroda powietrza eliminuje wycieki powietrza w pustych szczelinach

Pokrywa jest wsunięta w szynę prowadzącą

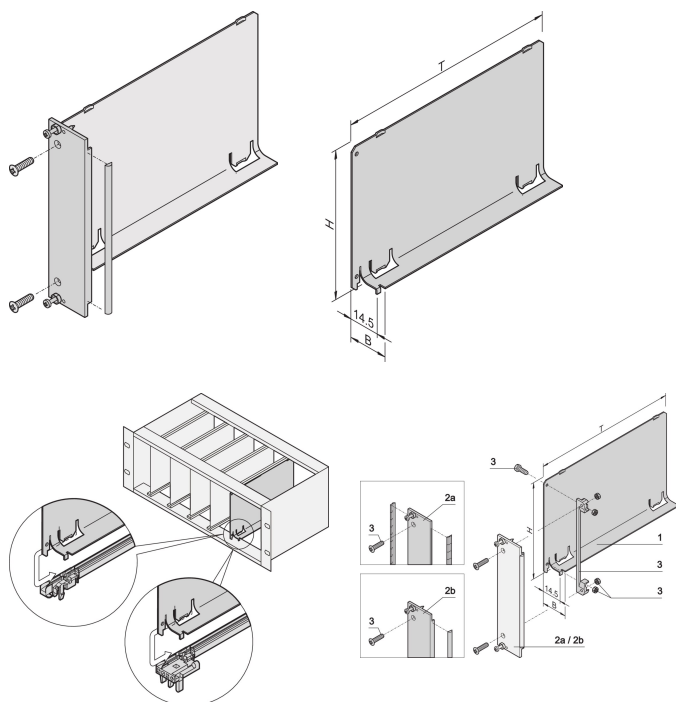

ATRYBUTY PRODUKTU

Wysokość stojaka: 6U

Głębokość: 160mm

Ekranowanie EMC: Nie (możliwość modernizacji)

Materiał: Aluminium

Rodzina produktów: EuropacPRO; RatiopacPRO; RatiopacPRO air; CompacPRO; PropacPRO; Inpac

Typ produktu: Przegroda powietrzna

Szerokość stojaka: 8HP

Typ: Z panelem przednim

Współpracuje z: Stojaki podrzędne; Obudowy

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products



DODATKOWE INFORMACJE O PRODUKCIE

Przegroda powietrzna dla głębokości 280 mm i dla tylnych płyt we/wy 80 mm dostępna na zamówienie.

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Marki w naszej ofercie:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE