


Pokrywa panelu bocznego EuropacPRO

Advanced EMC, 4U, 295 mm

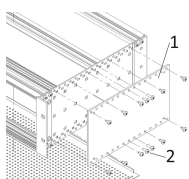

NUMER KATALOGOWY

24563-267

Aluminiowy panel boczny 3mm, aby zwiększyć efekt ekranowania EMC subracka poprzez pokrycie niepotrzebnych wycięć.

FUNKCJE

Osłony bocznych paneli zwiększają boczne ekranowanie RF

Montowane na zewnątrz standardowego panelu bocznego

W zestawie materiał montażowy



ATRYBUTY PRODUKTU

Wysokość stojaka: 4U

Głębokość: 295mm

Liczba opakowań: 2

Ekranowanie EMC: Tak

Wykończenie: Powierzchnia pasywowana

Długość: 295mm

Materiał: Aluminium

Rodzina produktów: EuropacPRO

Typ produktu: Panel boczny

Typ: Typ H

Współpracuje z: Stojaki podrzędne

Jednostka opakowania: Para

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products

may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DODATKOWE INFORMACJE O PRODUKCIE

Panel boczny i wspornik 19" są spawane na zimno. Tox-cold. Toxen = Technika clinching, bez dodatkowych pomocy. Odbywa się to za pomocą specjalnych narzędzi i wysokiego ciśnienia.

Wersja 9 U dostępna na życzenie.

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Marki w naszej ofercie:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE