


EuropacPRO 19" Subrack Kit for Backplane, Retrofit Shielding, 6 U, 415 mm

NUMER KATALOGOWY

24563-435

Nieekranowana podstawka do montażu na płycie montażowej.

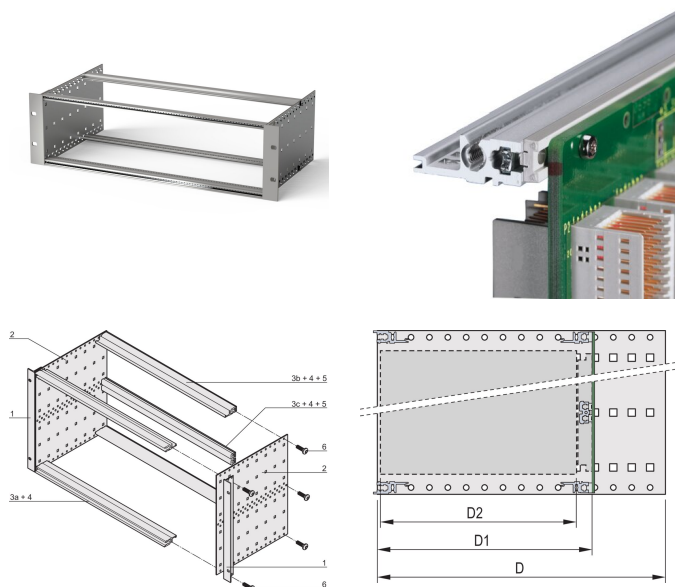

FUNKCJE

Podpórka z bocznym panelem typu F („elastyczny”), przedni wspornik 19” w zestawie, uchwyt 19” z regulacją głębokości sprzedawany oddzielnie (nie wchodzi w skład zestawu)

Tylna szyna pozioma do montażu na płycie montażowej z listwą izolacyjną

Aluminiowa konstrukcja

IP 20, zgodnie z IEC 60529

Modyfikacje, takie jak wycięcia, różne wykończenia lub dostępne wymiary

Dostarczane jako oszczędzające miejsce płaskie opakowanie

Szyna pozioma typu „light”

Wymiary wewnętrzne i zewnętrzne zgodnie z: IEC 60297-3-100, -101, IEEE 1101.1



ATRYBUTY PRODUKTU

Wysokość stojaka: 6U

Głębokość: 415mm

Liczba opakowań: 1

Do montażu: Płyta montażowa

Głębokość płyty: 160mm; 220mm; 280mm; 340mm

Typ uszczelki: Stal nierdzewna (możliwość modernizacji)

Uchwyt w zestawie: Nie

Montaż: Stojak

Zgodność z: IEC 60297-3-103

Ekranowanie EMC: Nie

Wykończenie: Anodyzowany; Powierzchnia pasywowana

Materiał: Aluminium

Typ produktu: Stojak podrzędny/podstawa montażowa

Szerokość stojaka: 84HP

Obciążenie statyczne: 11kg

Waga netto: 2.33kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DODATKOWE INFORMACJE O PRODUKCIE

Indywidualna konfiguracja: Szeroka gama wariantów wysokości, szerokości i głębokości; szyny prowadzące do szerokiej gamy zastosowań; opcje wnętrza; akcesoria i materiały montażowe.

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Marki w naszej ofercie:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE