

Front Panel Kit, Shielded, Bottom Hinged, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

NÚMERO DE CATÁLOGO

20848-601

U-profile front panel bottom hinged for textile gasket.


CARACTERÍSTICAS

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for subracks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

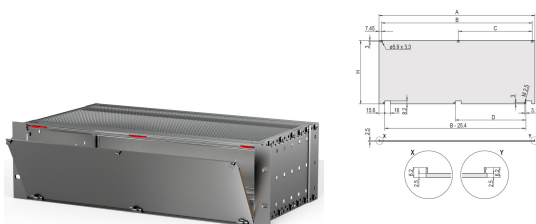

CARATERÍSTICAS DO PRODUTO

Rack Height: 3U

Accessory Type: Front panel

Rack Width: 84HP

Quantidade por embalagem: 1

Instalação: Hinged, Bottom

Gasket Type: Textile EMC

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Não

Em conformidade com: IEC 60297-3-101; IEEE 1101.1/10

Profundidade (D): 2.5mm

EMC Shielding: No (Retrofittable)

Acabamento: Anodized; Passivated

