

Front Panel, Refrofit Shielding, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

NÚMERO DE CATÁLOGO


30846-676

Flat front panel. Shieldable with stainless steel EMC gasket.

CARACTERÍSTICAS

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive

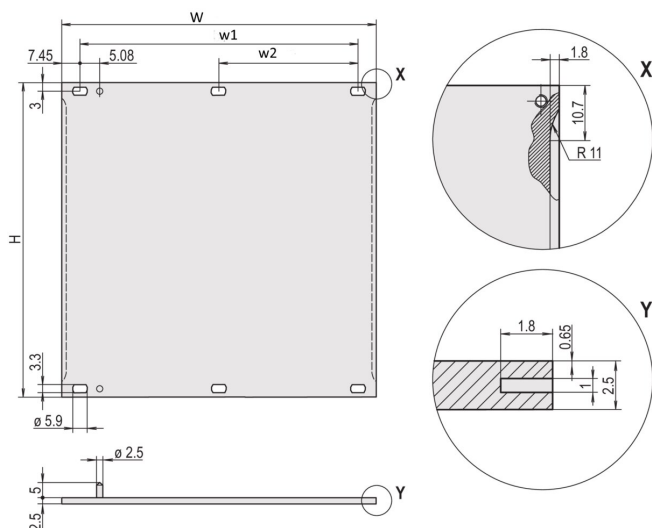

CARATERÍSTICAS DO PRODUTO

Rack Height: 3U

Rack Width: 84HP

Quantidade por embalagem: 1

Accessory Type: Front panel

Instalação: Screw-on Front

Gasket Type: Stainless Steel EMC

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Não

Em conformidade com: IEC 60297-3-101; IEEE 1101.1/10

Profundidade (D): 2.5mm

EMC Shielding: No (Retrofittable)

Acabamento: Anodized; Passivated

Altura (H): 128.4mm

Material: Alumínio

