


EuropacPRO Cover Plate for Bolting to Side Panel

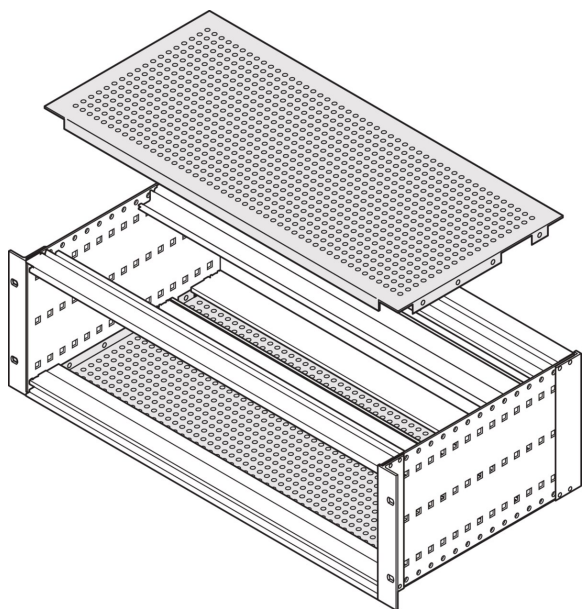

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

CARACTERÍSTICAS

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Perforation degree 58%

Suitable for use with all horizontal rails

Material:	Aluminio
Product Type:	Cover Plate
Família de produtos:	EuropacPRO
Acabamento:	Passivated
Tipo:	Perforated
Works With:	Sub racks



ESPECIFICAÇÕES

Número de catálogo	Rack Width	Profundidade	Quantidade por embalagem	Unidade de embalagem	Torque
24560-066	42HP	295mm	2	Pair	2.1N·m
24560-078	84HP	175mm	2	Pair	2.1N·m
24560-064	42HP	175mm	2	Pair	2.1N·m
24560-073	63HP	295mm	2	Pair	2.1N·m
24560-079	84HP	235mm	2	Pair	2.1N·m
24560-080	84HP	295mm	2	Pair	2.1N·m
24560-063	84HP	275mm	2	Pair	
24560-065	42HP	235mm	2	Pair	2.1N·m
24560-072	63HP	235mm	2	Pair	2.1N·m

Número de catálogo	Rack Width	Profundidade	Quantidade por embalagem	Unidade de embalagem	Torque
24560-081	84HP	355mm	2	Pair	2.1N·m
24560-082	84HP	415mm	2	Pair	2.1N·m
24560-071	63HP	175mm	2	Pair	2.1N·m
24560-083	84HP	475mm	2	Pair	2.1N·m
24560-061	42HP	275mm	2	Pair	
24579-090	42HP	277.75mm	2	Pair	2.1N·m
24579-092	84HP	277.75mm	2	Pair	2.1N·m
24560-062	63HP	275mm	2	Pair	

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE