


EuropacPRO Mounting Plate for Use With Cover Plate

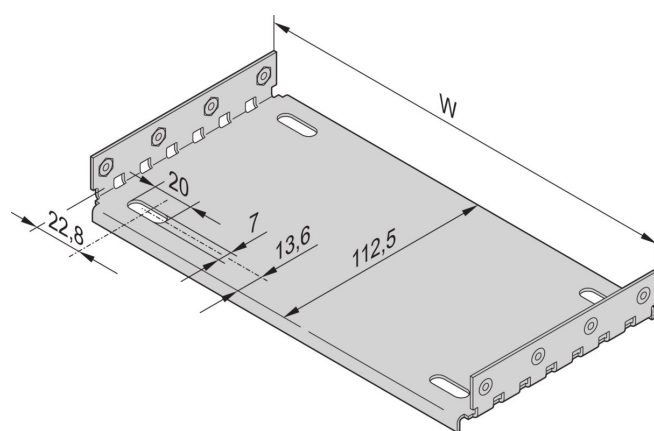

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CARACTERISTICAS

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

Material:	Aluminio
Família de produtos:	EuropacPRO
Product Type:	Mounting Plate
Works With:	Subracks



ESPECIFICAÇÕES

Número de catálogo	Rack Width	Quantidade por embalagem	Profundidade	Largura	Certifications
34563-004	84HP	1	112.5mm	431.35mm	RoHS
34563-019	63HP	1	172.5mm	324.67mm	RoHS
34563-014	42HP	1	172.5mm	217.99mm	RoHS
34563-009	28HP	1	172.5mm	146.88mm	RoHS
34563-003	63HP	1	112.5mm	324.67mm	RoHS
34563-002	42HP	1	112.5mm	217.99mm	RoHS

Número de catálogo	Rack Width	Quantidade por embalagem	Profundidade	Largura	Certifications
34563-001	28HP	1	112.5mm	146.88mm	RoHS
34563-024	84HP	1	172.5mm	431.35mm	RoHS
34563-044	84HP	1	412.5mm	431.35mm	
34563-042	84HP	1	352.5mm	431.35mm	
34563-028	84HP	1	292.5mm	431.35mm	
34563-026	84HP	1	232.5mm	431.35mm	

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE