


Guide Rail With DIN Connector Fixing

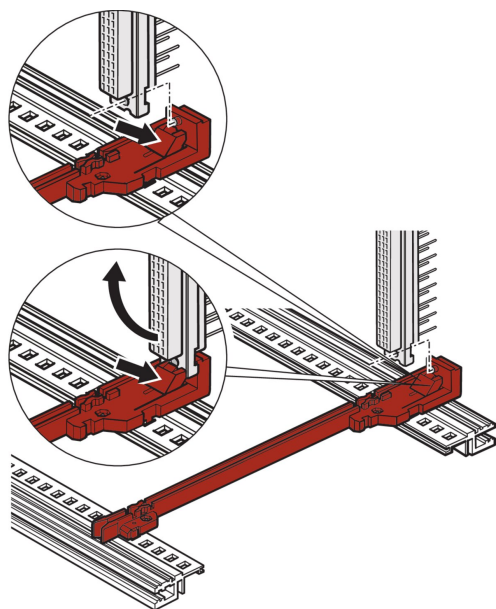

The the standard type guide rail with connector fixing allows the user to clip the DIN connectors (EN 60603-2 (DIN 41612)) directly onto the guide rails. Only applicable with Euroboards with the dimensions 100 x 160 mm and 100 x 220 mm. Suitable for RatiopacPRO/-AIR, PropacPRO, CompacPRO and EuropacPRO.

CARACTERÍSTICAS

Easy and economic mounting of connectors through snap connections as alternative to z-rails or horizontal rails with integrated z-rail

For single Euroboard format 100 × 160 mm or 100 × 220 mm; not suitable for double Euroboard format

Plastic guide rail, one piece, red, for 2 mm groove width

Can be clipped into horizontal rails in Al extrusion

Can be clipped into 1.5 mm thick plate

Storage temperature: from -40 °C ... 130 °C

Works With:	Subracks; Cases; Chassis
Família de produtos:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Product Type:	Guide Rail
Material:	Polybutylene Terephthalate
Cor:	Vermelho
Tipo:	Standard with DIN Connector



ESPECIFICAÇÕES

Número de catálogo	Quantidade por embalagem	Board Depth	Groove Width	Em conformidade com	Unidade de embalagem
64560-074	2	160mm	2	EN 60603-2 (DIN 41612)	Pair

Número de catálogo	Quantidade por embalagem	Board Depth	Groove Width	Em conformidade com	Unidade de embalagem
64560-075	2	220mm	2	EN 60603-2 (DIN 41612)	Pair

DETALHES ADICIONAIS DO PRODUTO

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE