

nVent CADDY Pyramid ST Fixed Strut Support



The nVent CADDY Pyramid ST Fixed Strut Support offers a simple and adaptable solution for mounting electrical and mechanical services on commercial rooftops. This support system is engineered to evenly distribute weight across the base, ensuring optimal load management. Additionally, the foam pad on the underside provides a low-abrasion interface that protects roof membranes, eliminating the need for a slip sheet.

Constructed with UV-stabilized base materials and hot-dip galvanized strut profiles, these supports deliver exceptional corrosion resistance. The standard strut profile attachment point accommodates a wide range of components, including conduit, pipe, and strut fasteners, allowing for secure and efficient installation.

CARACTERÍSTICAS

Effective load distribution across uneven surfaces

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Ready to use out-of-the-box, saving installation time and improving productivity

Available in multiple sizes and load ratings for tailored applications

Lightweight and easy to transport

Hot-dip galvanized and UV stabilized for long-lasting performance

Static Load Safety Factor: 3:1
Temperatura: -45 to 65 °C
Acabamento: Hot-Dip Galvanized
Material: Polietileno; Polypropylene; Aço



ESPECIFICAÇÕES

Table 1/2

Número de catálogo	Número do artigo	Comprimento 1 (L1)	Comprimento 2 (L2)	Altura (H)	Largura (W)	Surface Area
PSF6C	360463	152 mm	203 mm	122 mm	152 mm	26452mm ²
PSF10C	360464	254 mm	317.5 mm	122 mm	203 mm	59355mm ²
PSF16C	360466	406 mm	483 mm	122 mm	203 mm	91613mm ²

Número de catálogo	Número do artigo	Comprimento 1(L1)	Comprimento 2(L2)	Altura(H)	Largura(W)	SurfaceArea
PSF10D	360465	254 mm	317.5 mm	163 mm	203 mm	59355mm ²
PSF16D	360467	406 mm	483 mm	163 mm	203 mm	91613mm ²



Table 2/2

Número de catálogo	Número do artigo	Peso unitário	Static Load	Certifications
PSF6C	360463	0.5 kg	1334N	
PSF10C	360464	1 kg	4450N	ITB
PSF16C	360466	1.5 kg	6670N	ITB
PSF10D	360465	1.5 kg	4450N	ITB
PSF16D	360467	2 kg	6670N	ITB

DETALHES ADICIONAIS DO PRODUTO

Static load at 73.1 kPa (10.6 psi) roof loading. Contact project or roofing engineer for maximum allowable load on individual project roof system.

DIAGRAMAS

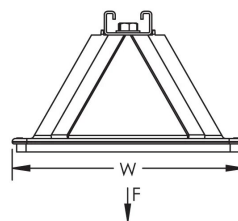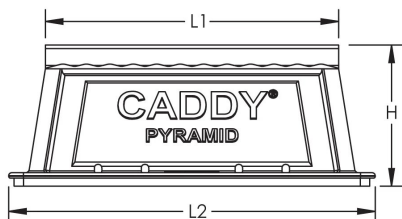

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência

técnica

Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

