


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, EN 50155

Subrack for Railway applications, conform to EN50155 standard, non-shielded.

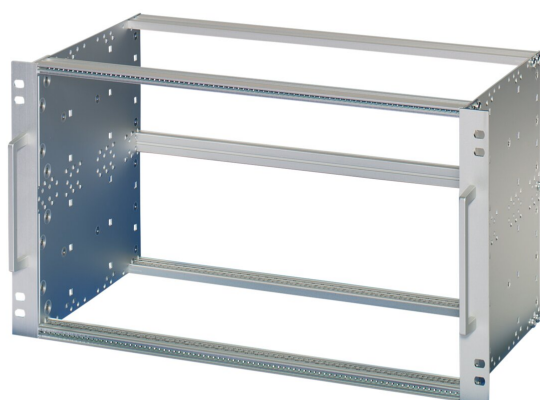

CARACTERISTICAS

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

The double 19" screwing position adds to additionally safety (NFF standard)

Supplied as space-saving flat-pack

Static Load: 15kg
Material: Alumínio
EMC Shielding: Não
Product Type: Subrack/Chassis



ESPECIFICAÇÕES

Table 1/2

Número de catálogo	Rack Height	Profundidade	Quantidade por embalagem	For Mounting	Board Depth	Gasket Type
21500-077	3U	235mm	1	Backplane	220mm	Textile EMC

Número de catálogo	RackHeight	Profundidade	Quantidade porembalagem	ForMounting	BoardDepth	GasketType
21500-078	6U	235mm	1	Backplane	220mm	Textile EMC

Table 2/2						
Número de catálogo	Shock and Vibration Tolerance	Inclui alça	Instalação	Em conformidade com	Acabamento	Rack Width
21500-077	5g (force)	Sim	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP
21500-078	5g (force)	Sim	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP

DETALHES ADICIONAIS DO PRODUTO

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE