


Panhead Screw, Pozidriv

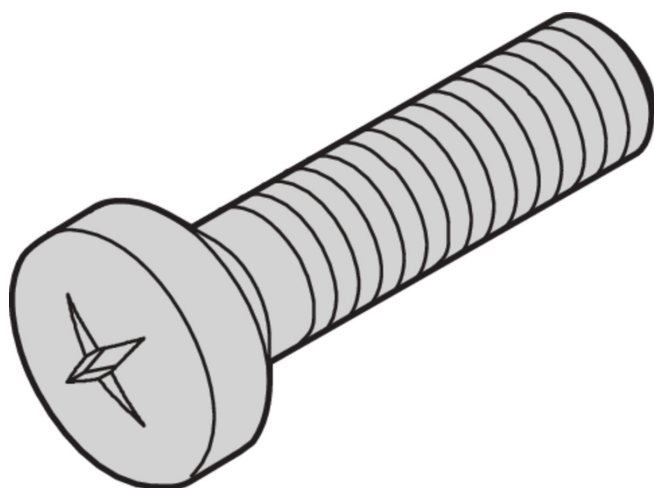

Good compromise between profile height and bearing area. Better load distribution than round heads. Compatible with automated assembly.

CARACTERISTICAS

Phillips screw offers a high level of torque to achieve quick and easy installation. The Phillips screw drive is more stable with the help of four contact points and better performing with screwdrivers. But unlike other kinds of screw drives, the Phillips drive is designed to cam out in which screw drive slips out of the cross head once the torque is needed to drive the screw exceeds a certain amount to avoid over tightening.

Pozidriv has a set of 45° radial indentations from the main cross recess leading to 4 additional contact points and greater stabilization to provide a greater contact surface. As a result, it decrease cam-out and wear, which allows greater torque to be applied.

Product Type: Screw
Material: Aço



ESPECIFICAÇÕES

Table 1/2

Número de catálogo	Diameter	Length	Acabamento	Quantidade por embalagem	Tamanho da rosca	Família de produtos
21102-024	3mm	6mm	Chapa de Aço Zincada	100	M3	
21120-150	5mm	10mm	Chapa de Aço Zincada	100	M5	
21101-314		5mm	Nickel Plated	100	M2.5	
21100-022	6mm	16mm	Chapa de Aço Zincada	100	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO

Número de catálogo	Diamet er	Len gt h	Acabament o	Quantidade por embalagem	Tamanho da rosca	Família de produtos
21120-203	6mm	16mm	Chapa de Aço Zincada	100	M6	
21100-021	6mm	16mm	Chapa de Aço Zincada	50	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21120-202	6mm	16mm	Chapa de Aço Zincada	50	M6	
21100-650	6mm	16mm	Chapa de Aço Zincada	100	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21101-219		6mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21101-069		8mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21101-220		10mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21101-221		12mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21100-788		12mm	Chapa de Aço Zincada	100	M5	EuropacPRO
21101-222		16mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit

Table 2/2

Número de catálogo	Tipo	Works With	Thread Type	Certification s
21102-024	Panhead Screw		Metric	RoHS
21120-150	Coding Block	Cabinet		RoHS
21101-314	Panhead Screw	Backplanes, Test Adapters		RoHS
21100-022	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		RoHS
21120-203	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		
21100-021	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		RoHS

Número de catálogo	Tipo	Works With	ThreadType	Certifications
21120-202	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		
21100-650	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		RoHS
21101-219	Panhead Screw	Backplanes, Test Adapters		RoHS
21101-069	Panhead Screw	Backplanes, Test Adapters		RoHS
21101-220	Panhead Screw	Backplanes, Test Adapters		RoHS
21101-221	Panhead Screw	Backplanes, Test Adapters		RoHS
21100-788	Panhead Screw	Subracks		RoHS
21101-222	Panhead Screw	Backplanes, Test Adapters		RoHS

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE