

Plug-In Unit Kit With IEL Handle, Shielded, Black, 6 U



Plug-in unit, with IEL inserter/extractor black handle, 6 U, front assembly. The U-shaped front panel enable shielding with a textile gasket.

CARACTERÍSTICAS

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

Material:	Aluminio
Acabamento:	Anodized; Passivated
Product Type:	Front Panel
Tipo:	Front Panel with Handle (PIU)



ESPECIFICAÇÕES

Table 1/2


Número de catálogo	Rack Width	Quantidade por embalagem	Tipo de alça	Instalação	Gasket Type	Front Finish
20848-592	4HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized
20848-598	12HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized
20848-594	6HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized
20848-596	8HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized
20848-597	10HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized

Table 2/2

Número de catálogo	Rear Finish	Treated Edges	Em conformidade com	EMC Shielding	Altura (H)	Rack Height	Largura (W)
20848-592	Etched	Não	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Sim	261.8mm	6U	20mm
20848-598	Etched	Não	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Sim	261.8mm	6U	60.6mm
20848-594	Etched	Não	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Sim	261.8mm	6U	30.1mm
20848-596	Etched	Não	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Sim	261.8mm	6U	40.3mm
20848-597	Etched	Não	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Sim	261.8mm	6U	50.5mm

DIAGRAMAS

6 U

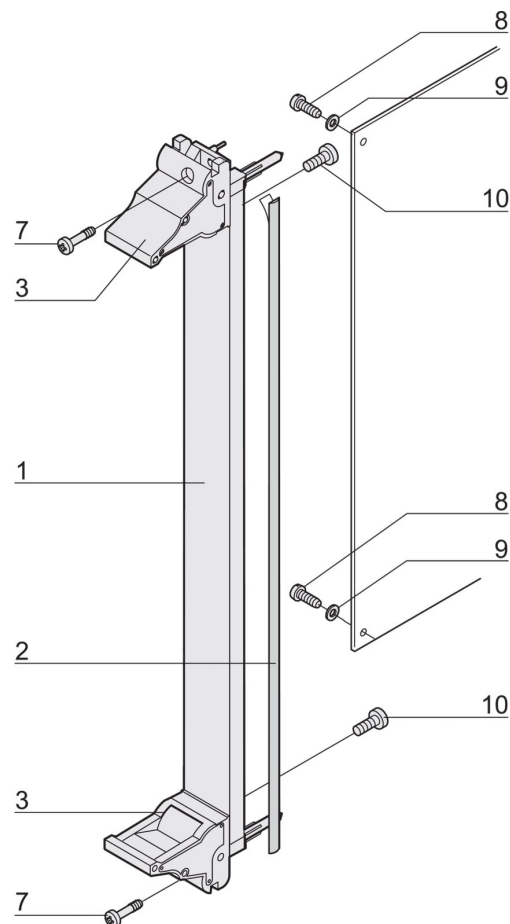

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE