


# Rear Panel for RatiopacPRO/PropacPRO, Perforated, Retrofit Shielding

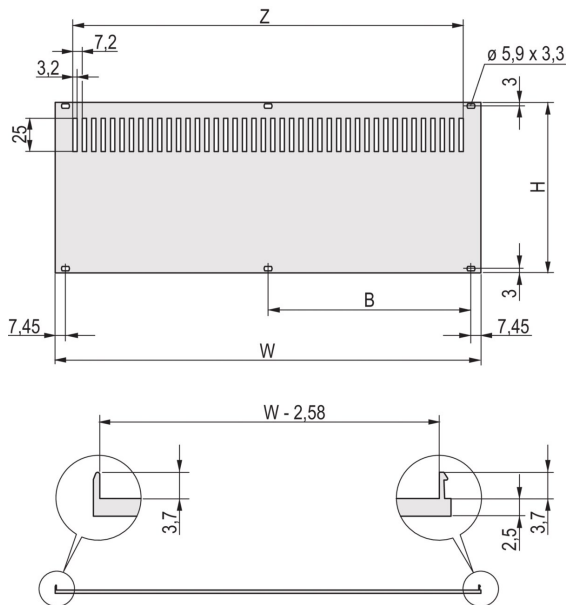

The perforated rear panel, Al, 2.5 mm is unshielded. The rear side is conductive.

## CARACTERISTICAS

Rear panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables mounting on horizontal rails

|                             |                              |
|-----------------------------|------------------------------|
| <b>Material:</b>            | Aluminio                     |
| <b>Acabamento:</b>          | Anodized; Passivated         |
| <b>Works With:</b>          | Cases                        |
| <b>Família de produtos:</b> | RatiopacPRO; RatiopacPRO AIR |
| <b>Tipo:</b>                | Rear Panel                   |
| <b>Product Type:</b>        | Side Panel                   |



## ESPECIFICAÇÕES

| Número de catálogo | Rack Height | Rack Width | Quantidade por embalagem | Altura  | Largura |
|--------------------|-------------|------------|--------------------------|---------|---------|
| 20848-744          | 5U          | 28HP       | 1                        | 220mm   | 141.9mm |
| 20848-656          | 4U          | 28HP       | 1                        | 168.9mm | 141.9mm |
| 20848-659          | 4U          | 84HP       | 1                        | 168.9mm | 426.4mm |
| 20848-658          | 4U          | 63HP       | 1                        | 168.9mm | 319.7mm |
| 20848-679          | 2U          | 28HP       | 1                        | 83.5mm  | 141.9mm |
| 20848-643          | 6U          | 84HP       | 1                        | 256mm   | 426.4mm |
| 20848-681          | 2U          | 63HP       | 1                        | 83.5mm  | 319.7mm |
| 20848-682          | 2U          | 84HP       | 1                        | 83.5mm  | 426.4mm |
| 20848-642          | 6U          | 63HP       | 1                        | 256mm   | 319.7mm |

| Número de catálogo | Rack Height | Rack Width | Quantidade por embalagem | Altura  | Largura |
|--------------------|-------------|------------|--------------------------|---------|---------|
| 20848-640          | 6U          | 28HP       | 1                        | 256mm   | 141.9mm |
| 20848-634          | 3U          | 42HP       | 1                        | 123.4mm | 213mm   |
| 20848-657          | 4U          | 42HP       | 1                        | 168.9mm | 213mm   |
| 20848-636          | 3U          | 84HP       | 1                        | 123.4mm | 426.4mm |
| 20848-745          | 5U          | 42HP       | 1                        | 220mm   | 213mm   |
| 20848-641          | 6U          | 42HP       | 1                        | 256mm   | 213mm   |
| 20848-746          | 5U          | 63HP       | 1                        | 220mm   | 319.7mm |
| 20848-635          | 3U          | 63HP       | 1                        | 123.4mm | 319.7mm |
| 20848-747          | 5U          | 84HP       | 1                        | 220mm   | 426.4mm |
| 20848-680          | 2U          | 42HP       | 1                        | 83.5mm  | 213mm   |
| 20848-633          | 3U          | 28HP       | 1                        | 123.4mm | 141.9mm |

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



O nosso forte portefólio de marcas:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**