

VPX Backplane

The nVent SCHROFF VPX Backplane have excellent Signal Integrity for highest data transfer rates.

CARACTERÍSTICAS


In accordance with: VITA 46.0 VPX base standard; VITA 46.3 Serial RapidIO on VPX; VITA 46.4 PCI Express on VPX Fabric Connector; VITA 46.7 Ethernet on VPX Fabric Connector; VITA 46.11 System Management for VPX

DIP switch for system slot settings

JTAG connections

Lockable aux utility and sense connectors

M4 power studs for power supply, max. 22 A per slot for each voltage

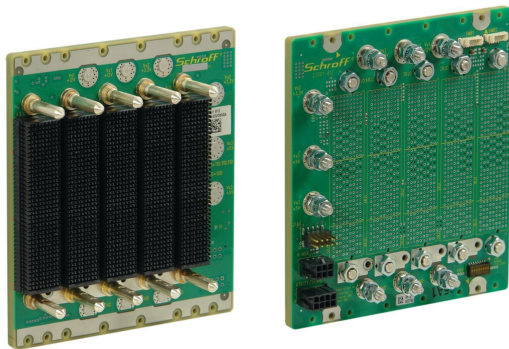

ESPECIFICAÇÕES

Table 1/2

Número de catálogo	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23001-834	Backplane	9	3U	VPX, VITA 65	5HP	MultiGig
23001-816	Backplane	10	6U	VPX, VITA 65	5HP	MultiGig
23001-815	Backplane	7	3U	VPX, VITA 65	5HP	MultiGig
23001-814	Backplane	7	3U	VPX, VITA 65	5HP	MultiGig
23001-812	Backplane	5	3U	VPX Full-mesh	4HP	MultiGig
23001-813	Backplane	5	3U	VPX Full-mesh	4HP	MultiGig

Table 2/2

Número de catálogo	Power Connector Type	Utility Connector Type	Largura	Quantidade por embalagem	Certifications
23001-834	Powerstuds M4	Microfit, 8-pin	253mm	1	VITA
23001-816	Powerstuds M4	Microfit, 8-pin	262.55mm	1	VITA, RoHS

Número de catálogo	Power Connector Type	Utility Connector Type	Largura	Quantidade por embalagem	Certifications
23001-815	Powerstuds M4	Microfit, 8-pin	186.46mm	1	RoHS, VITA
23001-814	Powerstuds M4	Microfit, 8-pin	186.46mm	1	VITA, RoHS
23001-812	Powerstuds M4	Microfit, 8-pin	120.67mm	1	VITA, RoHS
23001-813	Powerstuds M4	Microfit, 8-pin	120.67mm	1	RoHS, VITA

DETALHES ADICIONAIS DO PRODUTO

Other VPX Backplanes and custom VPX Backplane designs on request.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE