

PEMSA Wire Basket Tray Light Duty Ceiling Support



CARACTERISTICI

Ideal for tray widths up to 150mm

Side load access for cable installation

Fast and secure quick click installation features

IEC 61537 load rating and earthing compliant





SPECIFICAȚII

Table 1/2

Număr de catalog	Article Number	Material	Finish	Length 1 (L1)	Length 2 (L2)	Width (W)
WBT60COHBRKT	820300	Oțel	Electro galvanized	80 mm	55.2 mm	45 mm

Table 2/2

Număr de catalog	Article Number	Height (H)	Hole Size (HS)	Static Load
WBT60COHBRKT	820300	152 mm	11 mm	147N

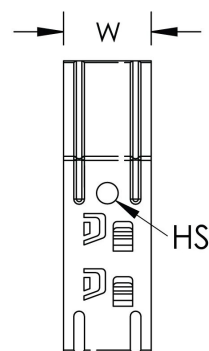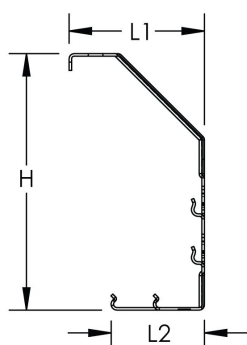

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

