


# Wire Basket Tray Waterfall

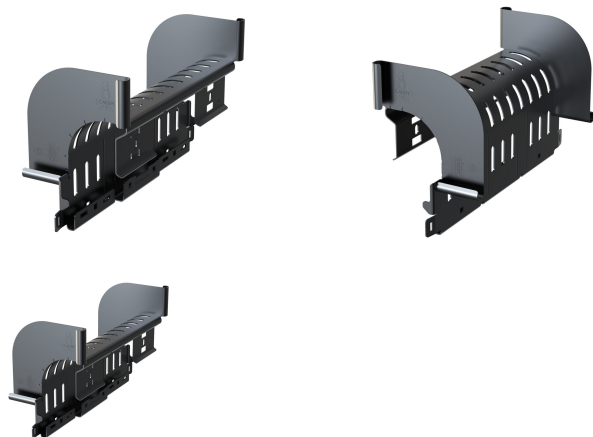

The nVent CADDY Wire Basket Tray Waterfall is a versatile, easy-to-install cable management solution for wire basket trays. Featuring innovative over-sidewall technology, installers can eliminate stress and pressure points on cable while removing the need to cut tray—saving valuable time on the job. Its flexible design and tool-free installation caters to both over-wall and flush-mount applications.

The Waterfall provides robust support and protection for large, high-density cable bundles and is ideal for managing copper, fiber optic, PoE and DAS cables. Available in both 12" and 20" options with a 120-degree bend radius, the sidewalls help funnel cables to an installer's desired location, creating a continuous pathway solution while maintaining a seamless and visually appealing finished result.

When necessary, the Waterfall has designated tie-off areas for grounding and bonding.

## CARACTERISTICI

Equipped with tie-down openings to facilitate bundled cable options

Powder coating protects against scratches or cable damage



Maintains a 120-degree bend, adhering to TIA-approved radius standards for all cable types

Standard finishes include black powder and electro-galvanized (zinc) coatings, with customization options for other colors upon request

Provides optimal support for high-performance data cable, up to and including fiber optic, Cat 5e, Cat 6, Cat 6A, and Cat 7

## SPECIFICAȚII

| Număr de catalog | Material | Color | Finish         | Length (L) | Height (H) | Width (W) | Unit Weight |
|------------------|----------|-------|----------------|------------|------------|-----------|-------------|
| WBTWTRFALL12BA   | Oțel     | Black | Vopsit Pulbere | 347mm      | 139 mm     | 196 mm    | 1.2 kg      |

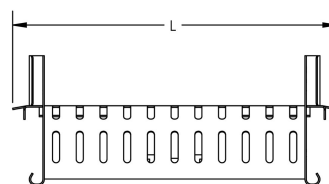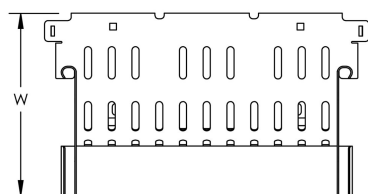

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

