

DR Symmetric Profile



CARACTERISTICI

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and 50022 and DIN 46277


RoHS compliant

Finish: Electrogalvanized

Material: Oțel


SPECIFICAȚII

Număr de catalog	Article Number	Height (H)	Width (W)	Length (L)	Thickness (T)	A	Unit Weight
DR7X2M	557800	35 mm	7.5 mm	2000mm	1 mm	4 mm	0.66 kg
DR7X3M	557810	35 mm	7.5 mm	3000mm	1 mm	4 mm	0.99 kg
DR5-5X2M	557700	15 mm	5.5 mm	2000mm	1 mm	2.25 mm	0.33 kg
DR15X3M	557910	35 mm	15 mm	3000mm	1.5 mm	4 mm	1.95 kg
DR15X2M	557900	35 mm	15 mm	2000mm	1.5 mm	4 mm	1.3 kg

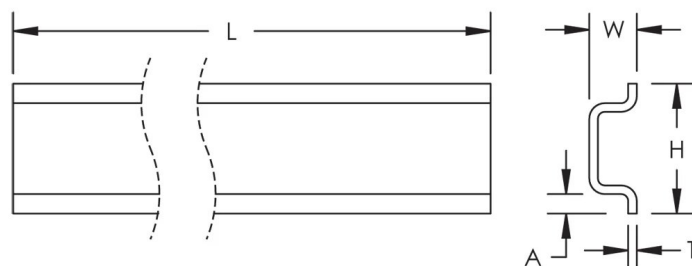

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE