

Cutie terminatie din oțel inoxidabil, SSTB



Gama de casete cu borne din oțel inoxidabil SSTB, cu grad de protecție IP 66, conține produse de stoc disponibile în numeroase dimensiuni diferite. Gama SSTB este bine adecvată pentru mediile de interior și exterior, datorită rezistenței sale la coroziune. Apa și praful sunt împiedicate să intre în cutia de terminatie, eliminându-se astfel riscul de defectare a componentelor și, cu aceasta, perioadele inutile de nefuncționare.

STANDARDE INDUSTRIALE

UL 508A Listed; Type 4X, 12, 13; File No. E92044

cUL Listed per CSA C22.2 No.0, No.0.4, No.14, No.94; Type 4X 12, 13; File No. E92044

NEMA/EEMAC Type 4X, 12, 13

IEC 62208 IP66

CE, UK CA, UL

CARACTERISTICI

Material: Oțel inoxidabil pregranulat, AISI 304L / AISI 316L (la cerere). Corp: 1 mm. Capac: 1.5 mm.

Corp: Pliat și sudat în linie. Patru bolțuri M6x13 pentru fixarea profilului inferior / plăcii de montare. Pentru a facilita instalarea, fiecare colț din spate al dulapului este marcat cu laser pentru a indica cu precizie unde să găuriți și să aplicați suporturile AWS pentru montare murală.

Garnitură: Etanșarea este asigurată de o garnitură din poliuretan injectat sau de o garnitură din silicon injectat.

Împământare: Șuruburi de legare la masă M8x18 mm în corp și capac, piulițe M8, șaibe și etichete de legare la masă.

Protecție: IP 66 | TYPE 4X, 12 | IK 08.

Finisaj: Oțel inoxidabil pregranulat, 400.

Livrare: Corp, capac, șuruburi capac, șuruburi de fixare, dopuri de acoperire și facilități de legare la masă.

Body Thickness:	1mm
Door Thickness:	1.5mm
Finish:	Lustruit

SPECIFICAȚII

Table 1/3

Număr de catalog	Height (H)	Width (W)	Depth (D)	Gasket Type	Material	Weight
SSTB305012-316	300mm	500mm	120mm	Silicone	Stainless Steel 316	5.1kg

Număr de catalog	Height (H)	Width (W)	Depth (D)	Gasket Type	Material	Weight
SSTB204012-316	200mm	400mm	120mm	Silicone	Stainless Steel 316	3.15kg
SSTB205012	200mm	500mm	120mm	Polyurethane	Stainless Steel 304	4.1kg
SSTB202008-316	200mm	200mm	80mm	Silicone	Stainless Steel 316	1.65kg
SSTB404012	400mm	400mm	120mm	Polyurethane	Stainless Steel 304	5.8kg
SSTB205012-316	200mm	500mm	120mm	Silicone	Stainless Steel 316	3.9kg
SSTB306012-316	300mm	600mm	120mm	Silicone	Stainless Steel 316	6.1kg
SSTB151512	150mm	150mm	120mm	Polyurethane	Stainless Steel 304	1.3kg
SSTB206012	200mm	600mm	120mm	Polyurethane	Stainless Steel 304	4.8kg
SSTB202008	200mm	200mm	80mm	Polyurethane	Stainless Steel 304	1.7kg
SSTB206012-316	200mm	600mm	120mm	Silicone	Stainless Steel 316	4.55kg
SSTB306012	300mm	600mm	120mm	Polyurethane	Stainless Steel 304	6.4kg
SSTB208012	200mm	800mm	120mm	Polyurethane	Stainless Steel 304	6.2kg
SSTB153012-316	150mm	300mm	120mm	Silicone	Stainless Steel 316	2.15kg
SSTB203008-316	200mm	300mm	80mm	Silicone	Stainless Steel 316	2.25kg
SSTB151512-316	150mm	150mm	120mm	Silicone	Stainless Steel 316	1.3kg
SSTB208012-316	200mm	800mm	120mm	Silicone	Stainless Steel 316	5.9kg
SSTB303008	300mm	300mm	80mm	Polyurethane	Stainless Steel 304	3.2kg
SSTB153012	150mm	300mm	120mm	Polyurethane	Stainless Steel 304	2.2kg
SSTB305012	300mm	500mm	120mm	Polyurethane	Stainless Steel 304	5.4kg

Table 2/3


Număr de catalog	Height (H)	Width (W)	Depth (D)	Gasket Type	Material	Weight
SSTB303008-316	300mm	300mm	80mm	Silicone	Stainless Steel 316	3.05kg
SSTB303012	300mm	300mm	120mm	Polyurethane	Stainless Steel 304	3.6kg
SSTB304012-316	300mm	400mm	120mm	Silicone	Stainless Steel 316	4.3kg
SSTB153008	150mm	300mm	80mm	Polyurethane	Stainless Steel 304	1.9kg
SSTB153008-316	150mm	300mm	80mm	Silicone	Stainless Steel 316	1.8kg
SSTB303012-316	300mm	300mm	120mm	Silicone	Stainless Steel 316	3.45kg
SSTB304012	300mm	400mm	120mm	Polyurethane	Stainless Steel 304	4.5kg
SSTB203012	200mm	300mm	120mm	Polyurethane	Stainless Steel 304	2.7kg
SSTB203012-316	200mm	300mm	120mm	Silicone	Stainless Steel 316	2.55kg
SSTB151508	150mm	150mm	80mm	Polyurethane	Stainless Steel 304	1.1kg
SSTB406012-316	400mm	600mm	120mm	Silicone	Stainless Steel 316	7.55kg
SSTB204008	200mm	400mm	80mm	Polyurethane	Stainless Steel 304	2.9kg
SSTB202012-316	200mm	200mm	120mm	Silicone	Stainless Steel 316	1.9kg
SSTB408012	400mm	800mm	120mm	Polyurethane	Stainless Steel 304	10.3kg
SSTB203008	200mm	300mm	80mm	Polyurethane	Stainless Steel 304	2.3kg

Număr de catalog	Height (H)	Width (W)	Depth (D)	Gasket Type	Material	Weight
SSTB204008-316	200mm	400mm	80mm	Silicone	Stainless Steel 316	2.8kg
SSTB406012	400mm	600mm	120mm	Polyurethane	Stainless Steel 304	8.1kg
SSTB204012	200mm	400mm	120mm	Polyurethane	Stainless Steel 304	3.3kg
SSTB202012	200mm	200mm	120mm	Polyurethane	Stainless Steel 304	2kg
SSTB151508-316	150mm	150mm	80mm	Silicone	Stainless Steel 316	1.1kg

Table 3/3

Număr de catalog	Height (H)	Width (W)	Depth (D)	Gasket Type	Material	Weight
SSTB404012-316	400mm	400mm	120mm	Silicone	Stainless Steel 316	5.4kg
SSTB408012-316	400mm	800mm	120mm	Silicone	Stainless Steel 316	9.7kg

DIAGRAMS

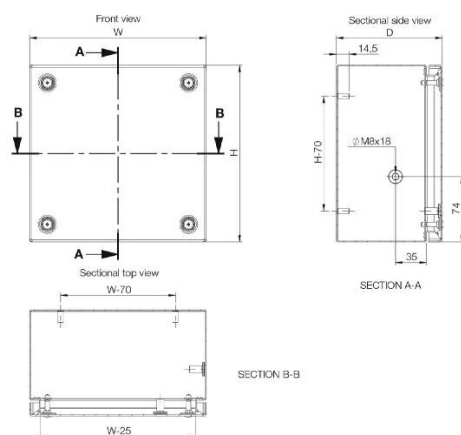

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE