

nVent LENTON Interlok Standard Grout-Fill Coupler, Plain



CARACTERISTICI

Designed to splice the same diameter bars

Smaller bars can be installed into the over-sized cavity end if required

Over-sized cavity allows for greater field tolerance

Taper-threaded end helps prevent movement of the reinforcing bars and eliminate misalignment

Requires less grout than most competitive systems

Material: Cast Iron
Finish: Plain
Packaging: Standard



SPECIFICAȚII

Table 1/2

Număr de catalog	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)
LK5		16 mm	#5	15M	65 mm	48 mm
LK16		16 mm	#5	15M	59 mm	41 mm
LK11	145605	36 mm	#11	35M	80 mm	62 mm
LK7	145585	22 mm	#7		65 mm	48 mm
LK6	145580	20 mm	#6	20M	65 mm	48 mm
LK8	145590	25 mm	#8	25M	68 mm	51 mm
LK20		20 mm	#6	20M	62 mm	45 mm
LK9	145595	28 mm	#9	30M	71 mm	54 mm
LK25		25 mm	#8	25M	68 mm	51 mm
LK10	145600	32 mm	#10		76 mm	59 mm


Număr de catalog	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)
LK12		38 mm			94 mm	70 mm
LK36		36 mm	#11	35M	81 mm	62 mm
LKT14	145611	43 mm	#14	45M	94 mm	70 mm
LK40		40 mm			94 mm	70 mm

Table 2/2							
Număr de catalog	Article Number	Length 1 (L1)	Length 2 (L2)	Bar Depth (BD)	Unit Weight	Package Quantity	Certifications
LK5		200 mm	156 mm	22mm	1.98 kg	12	
LK16		201 mm	168 mm	24mm	1.69 kg	110	IAPMO®-UES, LA City Approval
LK11	145605	305 mm	251 mm	43mm	3.63 kg	1	IAPMO®-UES, LA City Approval
LK7	145585	200 mm	156 mm	32mm	1.94 kg	1	LA City Approval, IAPMO®-UES
LK6	145580	200 mm	156 mm	28mm	1.96 kg	12	IAPMO®-UES, LA City Approval
LK8	145590	219 mm	178 mm	34mm	2.15 kg	8	IAPMO®-UES, LA City Approval
LK20		226 mm	178 mm	35mm	1.98 kg	12	IAPMO®-UES, LA City Approval
LK9	145595	248 mm	203 mm	38mm	2.44 kg	8	LA City Approval, IAPMO®-UES
LK25		228 mm	178 mm	40mm	2.26 kg	8	
LK10	145600	275 mm	229 mm	40mm	2.84 kg	8	LA City Approval, IAPMO®-UES
LK12		386 mm	324 mm	44mm	7.14 kg	4	
LK36		313 mm	251 mm	52mm	4.04 kg	8	
LKT14	145611	386 mm	324 mm	56mm	7.26 kg	4	IAPMO®-UES, LA City Approval
LK40		386 mm	324 mm	57mm	6.33 kg	4	

DETALII SUPLIMENTARE DESPRE PRODUS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

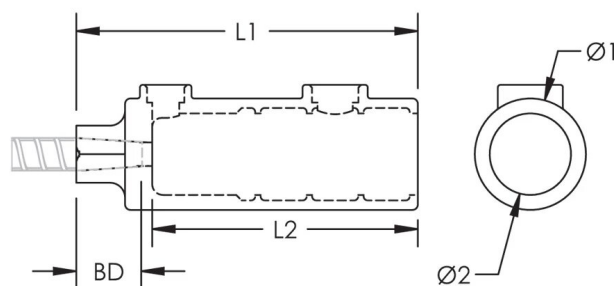

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE