

nVent LENTON Interlok Transition Grout-Fill Coupler, Plain



CARACTERISTICI

Designed to splice different diameter bars

Over-sized cavity allows for greater field tolerance

Taper-threaded end helps prevent movement of the reinforcing bars and eliminate misalignment

Requires less grout than most competitive systems

Material: Cast Iron

Finish: Plain

SPECIFICAȚII

Table 1/2

Număr de catalog	Product	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)
LK86	One-Piece Assembly	25 mm, 20 mm	#8, #6	25M, 20M	68 mm	51 mm
LK87	One-Piece Assembly	25 mm, 22 mm	#8, #7		68 mm	51 mm
LK97	One-Piece Assembly	28 mm, 22 mm	#9, #7		71 mm	54 mm
LK98	One-Piece Assembly	28 mm, 25 mm	#9, #8	30M, 25M	71 mm	54 mm
LK119	Two-Piece Assembly	36 mm, 28 mm	#11, #9	35M, 30M	79 mm	62 mm
LK109	One-Piece Assembly	32 mm, 28 mm	#10, #9		76 mm	59 mm

Număr de catalog	Product	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)
LK1110	One-Piece Assembly	36 mm, 32 mm	#11, #10		80 mm	62 mm
LK1410	One-Piece Assembly	43 mm, 32 mm	#14, #10		94 mm	70 mm
LK1411	One-Piece Assembly	43 mm, 36 mm	#14, #11	45M, 35M	94 mm	70 mm
LK1814T	One-Piece Assembly	57 mm, 43 mm	#18, #14	55M, 45M	114 mm	83 mm

Table 2/2


Număr de catalog	Length 1 (L1)	Length 2 (L2)	Bar Depth (BD)	Unit Weight	Package Quantity
LK86	219 mm	178 mm	28mm	2.29 kg	8
LK87	219 mm	178 mm	32mm	2.16 kg	8
LK97	248 mm	203 mm	32mm	2.44 kg	8
LK98	248 mm	203 mm	34mm	2.45 kg	8
LK119	373 mm	241 mm	38mm	4.56 kg	4
LK109	275 mm	229 mm	38mm	3.63 kg	8
LK1110	305 mm	251 mm	40mm	3.61 kg	8
LK1410	386 mm	324 mm	40mm	7.26 kg	4
LK1411	386 mm	324 mm	43mm	7.12 kg	4
LK1814T	518 mm	432 mm	56mm	19.96 kg	

Designed to Meet: AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

DETALII SUPLIMENTARE DESPRE PRODUS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

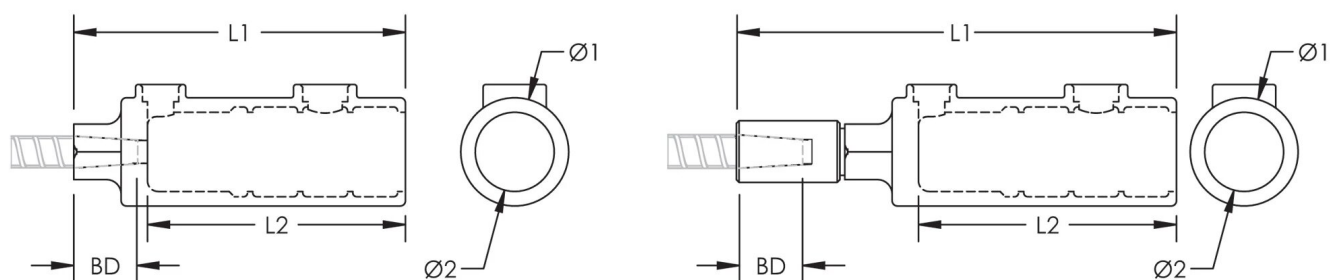

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE