


Collar Screw, Cross Recess/Slotted

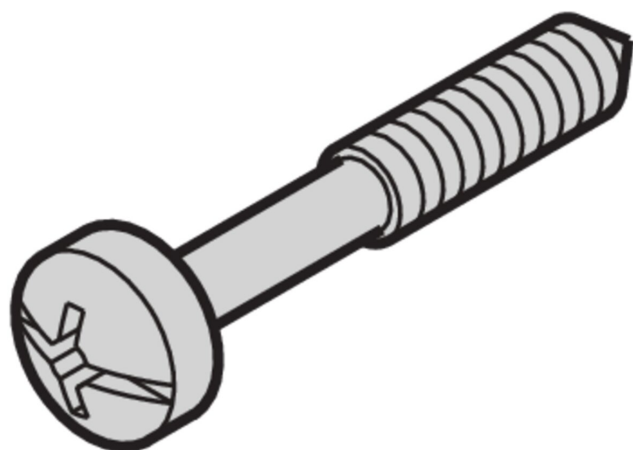

Integrated load spreading, replaces separate washer.
Improved joint consistency (less variation from washer misalignment) Better vibration resistance, especially with serrated collars

CARACTERISTICI

For assembly of partial width front panels and plug-in units

For EuropacPRO and RatiopacPRO

Cross Recess / Slotted combines advantages of both imprints: it offers a high level of torque to achieve quick and easy installation and enhances rotational leverage. It is convenient to use while offering universal tool compatibility.

Type: Screw
Product Type: Screw



SPECIFICAȚII

Table 1/2

Număr de catalog	Diameter	Length	Material	Finish	Package Quantity	Thread Size
21102-026	2.5mm	12.3mm	Oțel	Nickel Plated	100	M2.5
21101-102		12.3mm	Oțel	Zinc Top Coat	100	M2.5
21101-906		12.3mm	Stainless Steel		100	M2.5
21101-101		12.3mm	Oțel	Nickel Plated	100	M2.5
21101-323		11mm			100	M2.5

Table 2/2

Număr de catalog	Depth	Height	Width	Works With	Thread Type	Torque	Certifications
21102-026				Frame Type Plug-In Unit, Cassettes		0.3N·m	
21101-102	14.3mm	5mm	5mm	Front Panels	Metric	0.3N·m	RoHS
21101-906				Front Panels		0.3N·m	RoHS
21101-101	14.3mm	5mm	5mm	Front Panels	Metric	0.3N·m	RoHS
21101-323				Front Panels			

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE