


Countersunk Screw

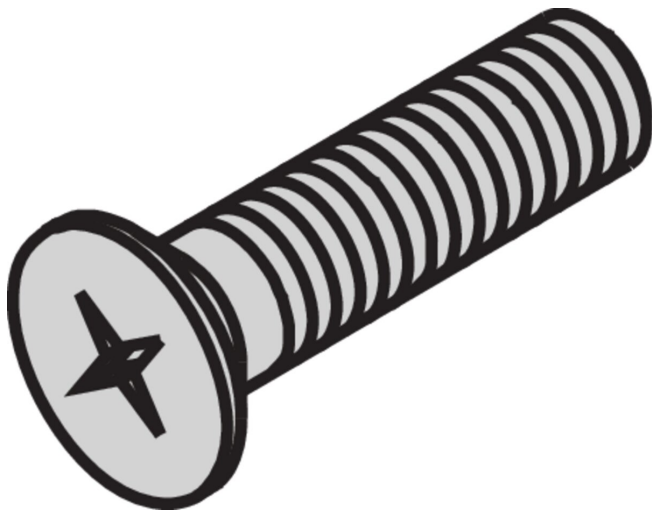

Flush surface, no interference with sliding parts. Self-centering in precision countersink. Clean external geometry (important for hygiene or airflow).

CARACTERISTICI

Countersunk screws are used for numerous mounting options in a subrack or desktop case.

Cross Recess imprint offers a high level of torque to achieve quick and easy installation

Torx imprint bears greater torque

The Torx star-shaped head prevents cam-out

Product Type: Screw



SPECIFICAȚII

Table 1/2

Număr de catalog	Length	Material	Finish	Package Quantity	Thread Size	Height
24560-139	5mm	Oțel	Oțel Zincat	100	M4	
24560-183	12mm	Oțel	Oțel Zincat	100	M5	
24560-182	12mm	Oțel	Oțel Zincat	4	M5	
24560-145	14mm	Oțel	Oțel Zincat	100	M4	
24560-164	8mm	Oțel	Nickel Plated	100	M2.5	4.7mm
24560-158	7.7mm	Oțel	Oțel Zincat	100	M2.5	
21100-542	8mm	Oțel	Nickel Plated	100	M3	
21100-429	8mm	Oțel	Nickel Plated	100	M2.5	
21100-649	10mm	Oțel	Oțel Zincat	100	M2.5	
21100-500	10mm	Oțel	Nickel Plated	100	M2.5	
21100-507	12mm	Oțel	Nickel Plated	100	M2.5	

Table 2/2

Număr de catalog	Type	Width	Works With	Thread Type	Torque
24560-139	Countersunk Screw		Front Panels		1.3N·m

Număr de catalog	Type	Width	Works With	Thread Type	Torque
24560-183	Countersunk Screw		Front Panels		2.4N·m
24560-182	Countersunk Screw		Front Panels		2.4N·m
24560-145	Countersunk Screw		Front Panels		2.4N·m
24560-164	Countersunk Screw	4.7mm	Front Panels	Metric	
24560-158	Countersunk Screw		Front Panels		
21100-542	Screw		Front Panels		
21100-429	Screw		Front Panels		
21100-649	Screw		Front Panels		
21100-500	Screw		Front Panels		
21100-507	Screw		Front Panels		

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE