


Front Panel Kit, Shielded, Bottom Hinged, 3 U, 42 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

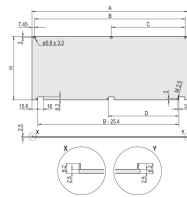

NUMĂR DE CATALOG

20848-599

U-profile front panel bottom hinged for textile gasket.

CARACTERISTICI

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for subracks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)



ATRIBUTE PRODUS

Rack Height: 3U

Accessory Type: Front panel

Rack Width: 42HP

Package Quantity: 1

Mounting: Hinged, Bottom

Gasket Type: Textile EMC

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Depth (D): 2.5mm

EMC Shielding: No (Retrofittable)

Finish: Anodized; Passivated

