


AirBender, Card Guide Insert, 70P Blockage, 4HP, 160mm, 10 Pieces Kit

NUMĂR DE CATALOG

24563-040

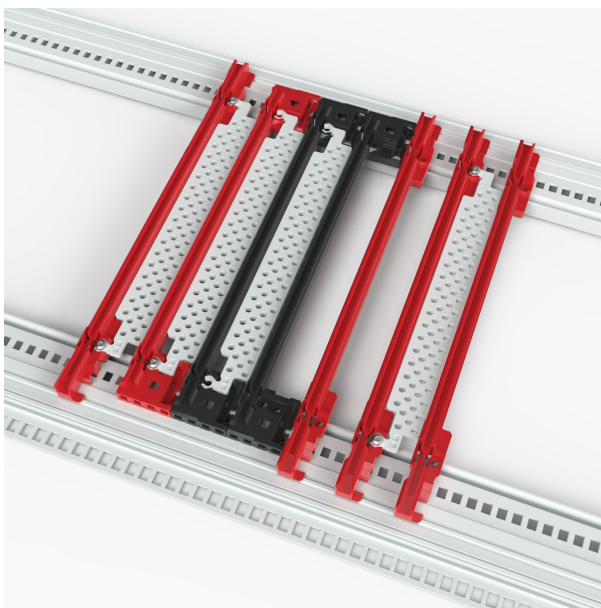

The nVent SCHROFF AirBender Inlay enhances cooling efficiency by up to 85% per slot by balancing airflow in mixed impedance environments. It is easy to install, reduces fan noise, and improves overall system performance.

CARACTERISTICI

AirBender card guide inserts enhance cooling efficiency in electronic systems by up to 85% per 4HP slot by balancing airflow in environments with mixed air impedances

70% blockage: The AirBender introduces additional air impedance in slots with less critical components, redirecting airflow to more vulnerable zones and ensuring better cooling outcomes for all cards

Easy installation: Simply clip the AirBender into nVent SCHROFF plastic card guides and optionally secure it with a screw

Favors reduced noise development from the fans by maintaining them at an efficient operating point

Air bender and CassettePRO cannot be used together in the same slot.

ATTRIBUTE PRODUS

Product Type: Air Baffle

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac

Works With: Sub racks; Cases; Systems

Rack Width: 4HP

Depth: 160mm

Material: Polycarbonate

Package Quantity: 10

Color: Grey

Complies With: EN 45545-2; UL® 94V-0

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DETALII SUPLIMENTARE DESPRE PRODUS

AirBenders with different blockage levels available on request.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE