


EuropacPRO 19" Subrack Kit for DIN Connector, Retrofit Shielding

Non-shielded subrack for Din Connector mounting EN 60603-2 (DIN 41612).

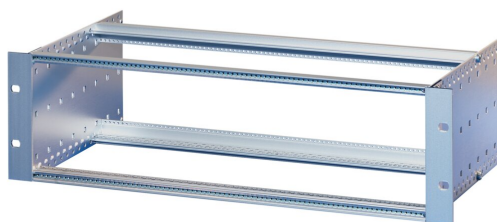

CARACTERISTICI

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Aluminum construction

IP 20, in accordance with IEC 60529

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Rear horizontal rails for connector mounting (IEC 60603-2 / DIN 41612)

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Horizontal rail type "light"

Material:	Aluminiu
Finish:	Anodized; Passivated
EMC Shielding:	No
Product Type:	Subrack/Chassis



SPECIFICAȚII

Table 1/2

Număr de catalog	Rack Height	Depth	Package Quantity	For Mounting	Board Depth	Gasket Type
24563-194	3U	355mm	1	DIN Connector	160mm, 220mm, 280mm, 340mm	Stainless Steel EMC (retrofittable)
24563-191	3U	175mm	1	DIN Connector	160mm	Stainless Steel EMC (retrofittable)
24563-192	3U	235mm	1	DIN Connector	160mm, 220mm	Stainless Steel EMC (retrofittable)
24563-494	6U	355mm	1	DIN Connector	160mm, 220mm, 280mm, 340mm	Stainless Steel EMC (retrofittable)
24563-491	6U	175mm	1	DIN Connector	160mm	Stainless Steel EMC (retrofittable)
24563-493	6U	295mm	1	DIN Connector	160mm, 220mm, 280mm	Stainless Steel EMC (retrofittable)
24563-193	3U	295mm	1	DIN Connector	160mm, 220mm, 280mm	Stainless Steel EMC (retrofittable)
24563-492	6U	235mm	1	DIN Connector	160mm, 220mm	Stainless Steel EMC (retrofittable)

Table 2/2

Număr de catalog	Handle Included	Mounting	Complies With	Rack Width	Static Load
24563-194	No	Rack	IEC 60297-3-103	84HP	11kg
24563-191	No	Rack	IEC 60297-3-103	84HP	11kg
24563-192	No	Rack	IEC 60297-3-103	84HP	11kg
24563-494	No	Rack	IEC 60297-3-103	84HP	11kg
24563-491	No	Rack	IEC 60297-3-103	84HP	11kg
24563-493	No	Rack	IEC 60297-3-103	84HP	11kg
24563-193	No	Rack	IEC 60297-3-103	84HP	11kg
24563-492	No	Rack	IEC 60297-3-103	84HP	11kg

DETALII SUPLIMENTARE DESPRE PRODUS

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE