


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, EN 50155

Subrack for Railway applications, conform to EN50155 standard, non-shielded.

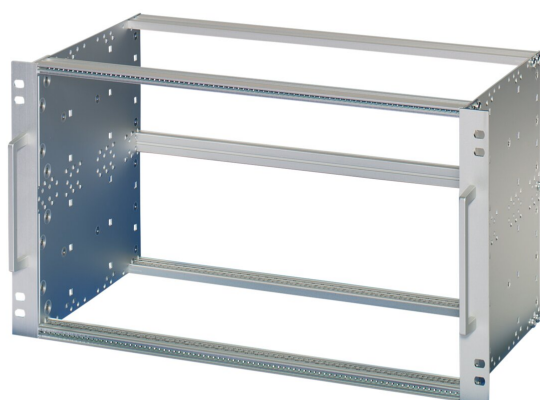

CARACTERISTICI

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (toxic-welded) and is especially suited for high mechanical stresses (vibration resistance)

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

The double 19" screwing position adds to additional safety (NFF standard)

Supplied as space-saving flat-pack

Static Load: 15kg
Material: Aluminu
EMC Shielding: No
Product Type: Subrack/Chassis



SPECIFICAȚII

Table 1/2

Număr de catalog	Rack Height	Depth	Package Quantity	For Mounting	Board Depth	Gasket Type
21500-077	3U	235mm	1	Backplane	220mm	Textile EMC

Număr de catalog	Rack Height	Depth	Package Quantity	For Mounting	Board Depth	Gasket Type
21500-078	6U	235mm	1	Backplane	220mm	Textile EMC

Table 2/2

Număr de catalog	Shock and Vibration Tolerance	Handle Included	Mounting	Complies With	Finish	Rack Width
21500-077	5g (force)	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP
21500-078	5g (force)	Yes	Rack	IEC 60297-3-103, EN 50155 part 12.2.11	Anodized, Passivated	84HP

DETALII SUPLIMENTARE DESPRE PRODUS

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE