

# EuropacPRO Advanced EMC Side Panel Cover


Aluminium Side panel 3mm to increase the EMC shielding effect of the subrack by covering the not needed cut-outs.

## CARACTERISTICI

Side panel covers for increased lateral RF shielding

Assembled on the outside of the standard side panel

Assembly material included

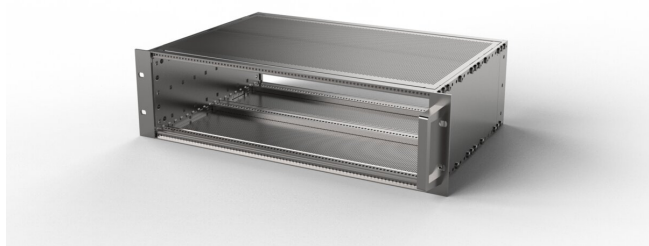

|                        |            |
|------------------------|------------|
| <b>Material:</b>       | Aluminiu   |
| <b>Product Family:</b> | EuropacPRO |
| <b>Finish:</b>         | Passivated |
| <b>Product Type:</b>   | Side Panel |
| <b>Works With:</b>     | Subracks   |
| <b>Type:</b>           | Type H     |
| <b>EMC Shielding:</b>  | Yes        |



## SPECIFICAȚII

Table 1/2

| Număr de catalog | Rack Height | Depth    | Package Quantity | Length   | Package Unit |
|------------------|-------------|----------|------------------|----------|--------------|
| 24563-256        | 3U          | 235mm    | 2                | 235mm    | Pair         |
| 24563-268        | 4U          | 355mm    | 2                | 355mm    | Pair         |
| 24563-257        | 3U          | 275mm    | 2                | 275mm    | Pair         |
| 24563-269        | 4U          | 415mm    | 2                | 415mm    | Pair         |
| 24563-267        | 4U          | 295mm    | 2                | 295mm    | Pair         |
| 24563-266        | 4U          | 235mm    | 2                | 235mm    | Pair         |
| 24563-270        | 4U          | 495mm    | 2                | 495mm    | Pair         |
| 24563-265        | 4U          | 175mm    | 2                | 175mm    | Pair         |
| 24563-275        | 6U          | 175mm    | 2                | 175mm    | Pair         |
| 24563-258        | 3U          | 277.75mm | 2                | 277.75mm | Pair         |
| 24563-276        | 6U          | 235mm    | 2                | 235mm    | Pair         |
| 24563-262        | 3U          | 495mm    | 2                | 495mm    | Pair         |
| 24563-277        | 6U          | 275mm    | 2                | 275mm    | Pair         |

| Număr de catalog | Rack Height | Depth    | Package Quantity | Length   | Package Unit |
|------------------|-------------|----------|------------------|----------|--------------|
| 24563-261        | 3U          | 415mm    | 2                | 415mm    | Pair         |
| 24563-278        | 6U          | 277.75mm | 2                | 277.75mm | Pair         |
| 24563-279        | 6U          | 295mm    | 2                | 295mm    | Pair         |
| 24563-260        | 3U          | 355mm    | 2                | 355mm    | Pair         |
| 24563-280        | 6U          | 355mm    | 2                | 355mm    | Pair         |
| 24563-281        | 6U          | 415mm    | 2                | 415mm    | Pair         |
| 24563-259        | 3U          | 295mm    | 2                | 295mm    | Pair         |

Table 2/2

| Număr de catalog | Rack Height | Depth | Package Quantity | Length | Package Unit |
|------------------|-------------|-------|------------------|--------|--------------|
| 24563-282        | 6U          | 495mm | 2                | 495mm  | Pair         |
| 24563-255        | 3U          | 175mm | 2                | 175mm  | Pair         |

## DETALII SUPLIMENTARE DESPRE PRODUS

Side panel and 19" bracket are tox-cold welded together. toxen = Clinching technique, without add aids. This takes place with special tools and high pressure.

9 U version available on request.

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**