


Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

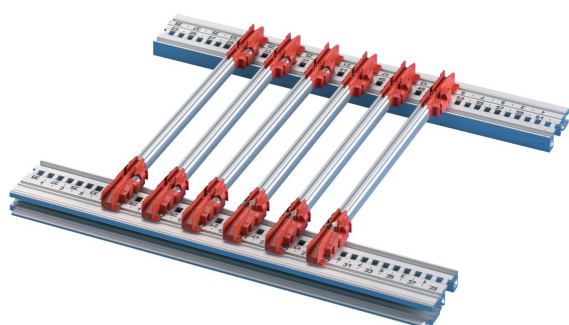

Guide rail mid-piece for individual multi-piece guide rails out of plastic or Aluminum extrusion. Suitable for Standard, Accessory, 4.4" PCB types and end pieces with coding.

CARACTERISTICI

Middle profile for mounting guide rails for 2 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Product Type: Guide Rail
Type: Middle Section



SPECIFICAȚII

Table 1/2

Număr de catalog	Material	Color	Package Quantity	Board Depth	Groove Width	Color Code
34560-891	Aluminiu	Silver	1	160mm	2	
34560-893	Aluminiu	Silver	1	280mm	2	
34564-891	PVC	Grey	1	160mm	2	RAL 7035
34564-893	PVC	Grey	1	280mm	2	RAL 7035
34564-900	PVC	Grey	1	1000mm	2	RAL 7035
34564-892	PVC	Grey	1	220mm	2	RAL 7035
34560-900	Aluminiu	Silver	1	1000mm	2	
34560-892	Aluminiu	Silver	1	220mm	2	

Număr de catalog	Finish	Works With
34560-891	Anodized	Subracks, Cases, Chassis
34560-893	Anodized	Subracks, Cases, Chassis
34564-891		Subracks, Cases, Chassis
34564-893		Subracks, Cases, Chassis
34564-900		Subracks, Cases, Chassis
34564-892		Subracks, Cases, Chassis
34560-900	Anodized	Subracks, Cases, Chassis
34560-892	Anodized	Subracks, Cases, Chassis

DETALII SUPLIMENTARE DESPRE PRODUS

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE