


Mounting Plate for 19" Case and Subrack

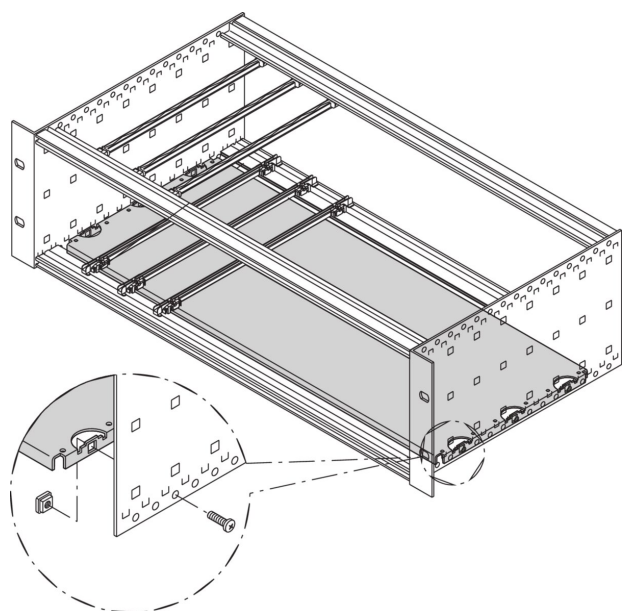

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CARACTERISTICI

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

Material: Aluminu
Product Type: Mounting Plate
Works With: Subracks



SPECIFICAȚII

Număr de catalog	Rack Width	Package Quantity	Depth	Product Family	Width	Certifications
34562-750	42HP	1	172.5m m	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	217.99m m	RoHS
34562-759	63HP	1	292.2m m	EuropacPRO, RatiopacPRO, CompacPRO	324.67m m	RoHS
34562-752	84HP	1	172.5m m	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	431.35m m	RoHS
34562-755	63HP	1	232.5m m	EuropacPRO, RatiopacPRO, CompacPRO	324.67m m	RoHS
34562-758	42HP	1	292.2m m	EuropacPRO, RatiopacPRO, CompacPRO	217.99m m	RoHS
34562-870	84HP	1	352.5m m	EuropacPRO	431.35m m	

Număr de catalog	Rack Width	Package Quantity	Depth	Product Family	Width	Certifications
34562-748	84HP	1	112.5m m	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67m m	RoHS
34562-747	63HP	1	112.5m m	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67m m	RoHS
34562-754	42HP	1	232.5m m	EuropacPRO, RatiopacPRO, CompacPRO	217.99m m	RoHS
34562-871	84HP	1	412.5m m	EuropacPRO	431.35m m	
34562-756	84HP	1	232.5m m	EuropacPRO, RatiopacPRO, CompacPRO	431.35m m	RoHS
34562-751	63HP	1	172.5m m	EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO	324.67m m	RoHS
34562-760	84HP	1	292.5m m	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	431.35m m	RoHS
34562-746	42HP	1	112.5m m	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	217.99m m	RoHS
34562-745	28HP	1	112.5m m	EuropacPRO, RatiopacPRO, CompacPRO	146.88m m	RoHS
34562-753	28HP	1	232.5m m	EuropacPRO, RatiopacPRO, CompacPRO	146.88m m	RoHS
34562-757	28HP	1	292.2m m	EuropacPRO, RatiopacPRO, CompacPRO	146.88m m	RoHS
34562-749	28HP	1	172.5m m	EuropacPRO, RatiopacPRO, CompacPRO	146.88m m	RoHS

DETALII SUPLIMENTARE DESPRE PRODUS

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE