


Panhead Screw, Pozidriv

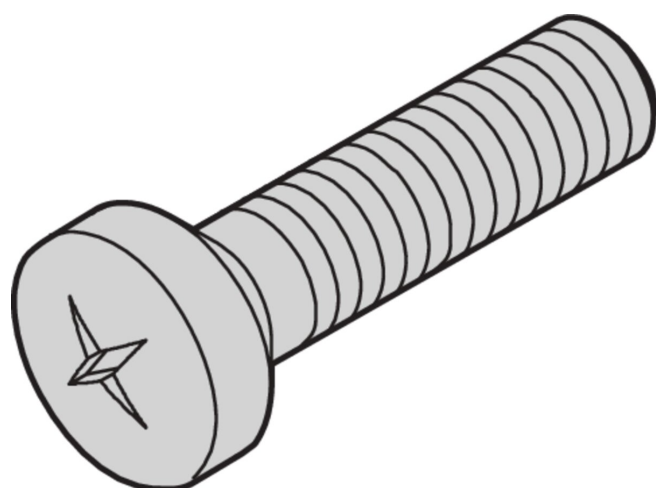

Good compromise between profile height and bearing area. Better load distribution than round heads. Compatible with automated assembly.

CARACTERISTICI

Phillips screw offers a high level of torque to achieve quick and easy installation. The Phillips screw drive is more stable with the help of four contact points and better performing with screwdrivers. But unlike other kinds of screw drives, the Phillips drive is designed to cam out in which screw drive slips out of the cross head once the torque is needed to drive the screw exceeds a certain amount to avoid over tightening.

Pozidriv has a set of 45° radial indentations from the main cross recess leading to 4 additional contact points and greater stabilization to provide a greater contact surface. As a result, it decrease cam-out and wear, which allows greater torque to be applied.

Product Type: Screw
Material: Oțel



SPECIFICAȚII

Table 1/2

Număr de catalog	Diamet er	Len gt h	Finish	Package Quantity	Thread Size	Product Family
21102-024	3mm	6mm	Oțel Zincat	100	M3	
21120-150	5mm	10mm	Oțel Zincat	100	M5	
21101-314		5mm	Nickel Plated	100	M2.5	
21100-022	6mm	16mm	Oțel Zincat	100	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21120-203	6mm	16mm	Oțel Zincat	100	M6	

Număr de catalog	Diameter	Length	Finish	Package Quantity	Thread Size	Product Family
21100-021	6mm	16mm	Oțel Zincat	50	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21120-202	6mm	16mm	Oțel Zincat	50	M6	
21100-650	6mm	16mm	Oțel Zincat	100	M6	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, Comptec, Inpac, MultipacPRO
21101-219		6mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21101-069		8mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21101-220		10mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21101-221		12mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit
21100-788		12mm	Oțel Zincat	100	M5	EuropacPRO
21101-222		16mm	Nickel Plated	100	M2.5	Frame Type Plug-In Unit

Table 2/2

Număr de catalog	Type	Works With	Thread Type	Certifications
21102-024	Panhead Screw		Metric	RoHS
21120-150	Coding Block	Cabinet		RoHS
21101-314	Panhead Screw	Backplanes, Test Adapters		RoHS
21100-022	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		RoHS
21120-203	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		
21100-021	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		RoHS
21120-202	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		
21100-650	Panhead Screw	Front Panels, Eurorack, Novastar, Varistar, Varistar CP		RoHS
21101-219	Panhead Screw	Backplanes, Test Adapters		RoHS
21101-069	Panhead Screw	Backplanes, Test Adapters		RoHS
21101-220	Panhead Screw	Backplanes, Test Adapters		RoHS
21101-221	Panhead Screw	Backplanes, Test Adapters		RoHS
21100-788	Panhead Screw	Subracks		RoHS
21101-222	Panhead Screw	Backplanes, Test Adapters		RoHS

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE