

Plug-In Unit Kit With IEL Handle, Shielded, Black, 3 U



Plug-in unit, with IEL inserter/extractor black handle, 3 U, front assembly. The U-shaped front panel enable shielding with a textile gasket.

CARACTERISTICI

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

Material: Aluminu
Finish: Anodized; Passivated
Product Type: Front Panel
Type: Front Panel with Handle (PIU)



SPECIFICAȚII

Table 1/2

Număr de catalog	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
20848-585	4HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-591	12HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-590	10HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-589	8HP	1	IEL	Screw-on Front	Textile EMC	Anodized
20848-587	6HP	1	IEL	Screw-on Front	Textile EMC	Anodized


Table 2/2

Număr de catalog	Rear Finish	Treated Edges	Complies With	EMC Shielding	Height (H)	Rack Height	Width (W)
20848-585	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U	20mm

Număr de catalog	Rear Finish	Treated Edges	Complies With	EMC Shielding	Height (H)	Rack Height	Width (W)
20848-591	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U	60.6mm
20848-590	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U	50.5mm
20848-589	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U	40.3mm
20848-587	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Yes	128.4mm	3U	30.1mm

DIAGRAMS

3U

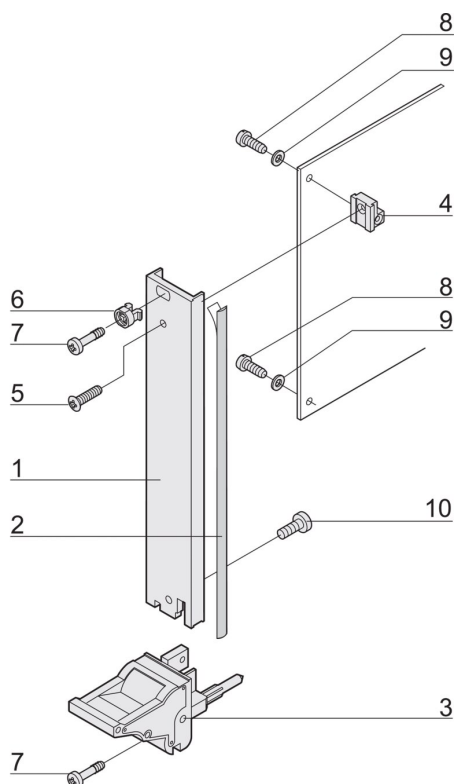

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE