


RatiopacPRO EMC Front Panel, Slotted, Shielded

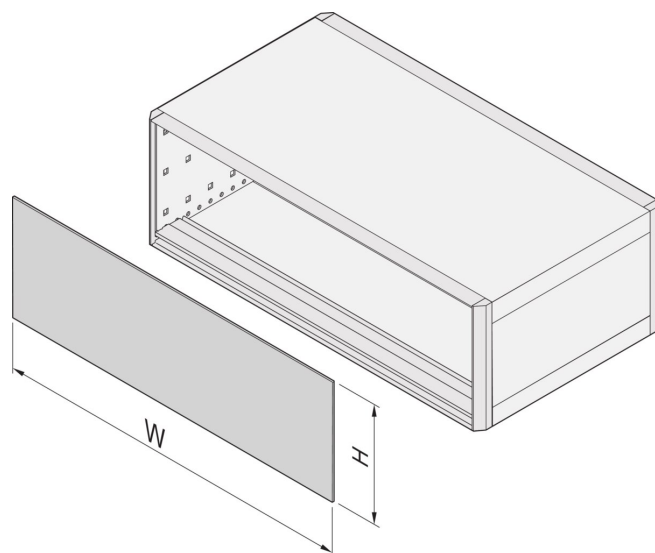

The EMC front panel can be inserted in special horizontal rails with an elevation. No screws are needed for the fixing. The design enable a users to use a front foil.

CARACTERISTICI

Fixing does not require screws

Special horizontal rails cover the edges of the front panel (top and bottom) and prevent bowing of the front panel

Material: Aluminu
Finish: Anodized; Passivated
Accessory Type: Front panel
Product Type: Front Panel



SPECIFICAȚII

Table 1/2

Număr de catalog	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
24572-609	4U	63HP	1	Anodized	Conductive	No
24572-610	4U	84HP	1	Anodized	Conductive	No
24572-604	3U	42HP	1	Anodized	Conductive	No
24572-599	2U	28HP	1	Anodized	Conductive	No
24572-607	4U	28HP	1	Anodized	Conductive	No
24572-600	2U	42HP	1	Anodized	Conductive	No
24572-601	2U	63HP	1	Anodized	Conductive	No
24572-605	3U	63HP	1	Anodized	Conductive	No
24572-602	2U	84HP	1	Anodized	Conductive	No
24572-603	3U	28HP	1	Anodized	Conductive	No
24572-608	4U	42HP	1	Anodized	Conductive	No

Număr de catalog	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
24572-606	3U	84HP	1	Anodized	Conductive	No

Table 2/2

Număr de catalog	Depth	Height	Width
24572-609	2.5mm	172.9mm	319.7mm
24572-610	2.5mm	172.9mm	426.4mm
24572-604	2.5mm	128.4mm	213.2mm
24572-599	2.5mm	84mm	141.9mm
24572-607	2.5mm	172.9mm	141.9mm
24572-600	2.5mm	84mm	213.2mm
24572-601	2.5mm	84mm	319.7mm
24572-605	2.5mm	128.4mm	319.7mm
24572-602	2.5mm	84mm	426.4mm
24572-603	2.5mm	128.4mm	141.9mm
24572-608	2.5mm	172.9mm	213.2mm
24572-606	2.5mm	128.4mm	426.4mm

DETALII SUPLIMENTARE DESPRE PRODUS

To obtain a shielded case, all EMC sealings must be fitted (front panel/rear panel - side panel; side panel - cover plate; front panel/rear panel - horizontal rail; horizontal rail - horizontal rail).

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE