

# A12 Standardövergångskopplare, slät, världsomspännande design



## DESIGN

Monteras snabbt och enkelt

Designed to splice different diameter bars where the second bar can be rotated and is not restricted in its axial direction

Slim design maintains concrete cover

**Yta:** Standard  
**Material:** Stål  
**Designversion:** Globalt (globalt tillgängligt material)



## SPECIFIKATIONER

Table 1/4

| Katalognummer | Armeringsstorlek, metrisk | Armeringsstorlek, USA | Armeringsstorlek, Kanada | Sexkantsbredd (W) | Diameter (Ø) | Längd (L) |
|---------------|---------------------------|-----------------------|--------------------------|-------------------|--------------|-----------|
| EL1210A12N    | 12 mm, 10 mm              | #4, #3                |                          | 17 mm             |              | 55mm      |
| EL1614A12N    | 16 mm, 14 mm              |                       |                          | 22 mm             |              | 64mm      |
| EL1612A12N    | 16 mm, 12 mm              | #5, #4                | 15 MILJONER EURO, 10M.   | 22 mm             |              | 61mm      |
| EL1412A12N    | 14 mm, 12 mm              |                       |                          | 22 mm             |              | 57mm      |
| EL1410A12N    | 14 mm, 10 mm              |                       |                          | 22 mm             |              | 57mm      |
| EL1610A12N    | 16 mm, 10 mm              | #5, #3                |                          | 22 mm             |              | 61mm      |
| EL1814A12N    | 18 mm, 14 mm              |                       |                          | 27 mm             |              | 69mm      |

| Katalognummer | Armeringsstorlek, metrisk | Armeringsstorlek, USA | Armeringsstorlek, Kanada           | Sexkantsbredd (W) | Diameter (Ø) | Längd (L) |
|---------------|---------------------------|-----------------------|------------------------------------|-------------------|--------------|-----------|
| EL1812A12N    | 18 mm, 12 mm              |                       |                                    | 27 mm             |              | 66mm      |
| EL1810A12N    | 18 mm, 10 mm              |                       |                                    | 27 mm             |              | 66mm      |
| EL1816A12N    | 18 mm, 16 mm              |                       |                                    | 27 mm             |              | 71mm      |
| EL2012A12N    | 20 mm, 12 mm              | #6, #4                | 20 MILJONER EURO, 10M.             | 27 mm             |              | 74mm      |
| EL2014A12N    | 20 mm, 14 mm              |                       |                                    | 27 mm             |              | 77mm      |
| EL2018A12N    | 20 mm, 18 mm              |                       |                                    | 27 mm             |              | 85mm      |
| EL2010A12N    | 20 mm, 10 mm              | #6, #3                |                                    | 27 mm             |              | 74mm      |
| EL2016A12N    | 20 mm, 16 mm              | #6, #5                | 20 MILJONER EURO, 15 MILJONER EURO | 27 mm             |              | 80mm      |
| EL2212A12N    | 22 mm, 12 mm              | #7, #4                |                                    | 30 mm             |              | 77mm      |
| EL2216A12N    | 22 mm, 16 mm              | #7, #5                |                                    | 30 mm             |              | 83mm      |
| EL2210A12N    | 22 mm, 10 mm              | #7, #3                |                                    | 30 mm             |              | 77mm      |
| EL2214A12N    | 22 mm, 14 mm              |                       |                                    | 30 mm             |              | 80mm      |
| EL2218A12N    | 22 mm, 18 mm              |                       |                                    | 30 mm             |              | 87mm      |

Table 2/4

| Katalognummer | Armeringsstorlek, metrisk | Armeringsstorlek, USA | Armeringsstorlek, Kanada           | Sexkantsbredd (W) | Diameter (Ø) | Längd (L) |
|---------------|---------------------------|-----------------------|------------------------------------|-------------------|--------------|-----------|
| EL2220A12N    | 22 mm, 20 mm              | #7, #6                |                                    | 30 mm             |              | 95mm      |
| EL2512A12N    | 25 mm, 12 mm              | #8, #4                | 25 MILJONER EURO, 10M.             |                   | 35 mm        | 81mm      |
| EL2510A12N    | 25 mm, 10 mm              | #8, #3                |                                    |                   | 35 mm        | 81mm      |
| EL2514A12N    | 25 mm, 14 mm              |                       |                                    |                   | 35 mm        | 83mm      |
| EL2516A12N    | 25 mm, 16 mm              | #8, #5                | 25 MILJONER EURO, 15 MILJONER EURO |                   | 35 mm        | 86mm      |
| EL2518A12N    | 25 mm, 18 mm              |                       |                                    |                   | 35 mm        | 90mm      |
| EL2522A12N    | 25 mm, 22 mm              | #8, #7                |                                    |                   | 35 mm        | 100mm     |
| EL2520A12N    | 25 mm, 20 mm              | #8, #6                | 25 MILJONER EURO, 20 MILJONER EURO |                   | 35 mm        | 98mm      |
| EL2814A12N    | 28 mm, 14 mm              |                       |                                    |                   | 40 mm        | 86mm      |
| EL2816A12N    | 28 mm, 16 mm              | #9, #5                | 30 MILJONER EURO, 15 MILJONER EURO |                   | 40 mm        | 88mm      |
| EL2818A12N    | 28 mm, 18 mm              |                       |                                    |                   | 40 mm        | 93mm      |
| EL3016A12N    | 30 mm, 16 mm              |                       |                                    |                   | 40 mm        | 99mm      |
| EL2825A12N    | 28 mm, 25 mm              | #9, #8                | 30 MILJONER EURO, 25 MILJONER EURO |                   | 40 mm        | 104mm     |
| EL3028A12N    | 30 mm, 28 mm              |                       |                                    |                   | 40 mm        | 117mm     |

| Katalognummer | Armeringsstorlek, metrisk | Armeringsstorlek, USA | Armeringsstorlek, Kanada           | Sexkantsbredd (W) | Diameter (Ø) | Längd (L) |
|---------------|---------------------------|-----------------------|------------------------------------|-------------------|--------------|-----------|
| EL2820A12N    | 28 mm, 20 mm              | #9, #6                | 30 MILJONER EURO, 20 MILJONER EURO |                   | 40 mm        | 101mm     |
| EL3018A12N    | 30 mm, 18 mm              |                       |                                    |                   | 40 mm        | 103mm     |
| EL2822A12N    | 28 mm, 22 mm              | #9, #7                |                                    |                   | 40 mm        | 103mm     |
| EL3025A12N    | 30 mm, 25 mm              |                       |                                    |                   | 40 mm        | 115mm     |
| EL3020A12N    | 30 mm, 20 mm              |                       |                                    |                   | 40 mm        | 110mm     |
| EL3022A12N    | 30 mm, 22 mm              |                       |                                    |                   | 40 mm        | 113mm     |

Table 3/4

| Katalognummer | Armeringsstorlek, metrisk | Armeringsstorlek, USA | Armeringsstorlek, Kanada | Sexkantsbredd (W) | Diameter (Ø) | Längd (L) |
|---------------|---------------------------|-----------------------|--------------------------|-------------------|--------------|-----------|
| EL3216A12N    | 32 mm, 16 mm              | #10, #5               |                          |                   | 45 mm        | 92mm      |
| EL3218A12N    | 32 mm, 18 mm              |                       |                          |                   | 45 mm        | 98mm      |
| EL3228A12N    | 32 mm, 28 mm              | #10, #9               |                          |                   | 45 mm        | 110mm     |
| EL4038A12N    | 40 mm, 38 mm              |                       |                          |                   | 55 mm        | 133mm     |
| EL3432A12N    | 34 mm, 32 mm              |                       |                          |                   | 50 mm        | 123mm     |
| EL3836A12N    | 38 mm, 36 mm              | #12, #11              |                          |                   | 55 mm        | 128mm     |
| EL3632A12N    | 36 mm, 32 mm              | #11, #10              |                          |                   | 50 mm        | 120mm     |
| EL4036A12N    | 40 mm, 36 mm              |                       |                          |                   | 55 mm        | 132mm     |
| EL3634A12N    | 36 mm, 34 mm              |                       |                          |                   | 50 mm        | 130mm     |
| EL3225A12N    | 32 mm, 25 mm              | #10, #8               |                          |                   | 45 mm        | 109mm     |
| EL3428A12N    | 34 mm, 28 mm              |                       |                          |                   | 50 mm        | 120mm     |
| EL3230A12N    | 32 mm, 30 mm              |                       |                          |                   | 45 mm        | 120mm     |
| EL3832A12N    | 38 mm, 32 mm              |                       |                          |                   | 55 mm        | 122mm     |
| EL3220A12N    | 32 mm, 20 mm              | #10, #6               |                          |                   | 45 mm        | 105mm     |
| EL3834A12N    | 38 mm, 34 mm              |                       |                          |                   | 55 mm        | 132mm     |
| EL4034A12N    | 40 mm, 34 mm              |                       |                          |                   | 55 mm        | 136mm     |
| EL3430A12N    | 34 mm, 30 mm              |                       |                          |                   | 50 mm        | 131mm     |
| EL4032A12N    | 40 mm, 32 mm              |                       |                          |                   | 55 mm        | 126mm     |
| EL3222A12N    | 32 mm, 22 mm              | #10, #7               |                          |                   | 45 mm        | 107mm     |
| EL3628A12N    | 36 mm, 28 mm              | #11, #9               | 35M, 30 MILJONER EURO    |                   | 50 mm        | 118mm     |

Table 4/4

| Katalognummer | Armeringsstorlek, metrisk | Armeringsstorlek, USA | Armeringsstorlek, Kanada | Sexkantsbredd (W) | Diameter (Ø) | Längd (L) |
|---------------|---------------------------|-----------------------|--------------------------|-------------------|--------------|-----------|
| EL3630A12N    | 36 mm, 30 mm              |                       |                          |                   | 50 mm        | 128mm     |

| Katalognummer | Armeringsstorlek, metrisk | Armeringsstorlek, USA | Armeringsstorlek, Kanada | Sexkantsbredd (W) | Diameter (Ø) | Längd (L) |
|---------------|---------------------------|-----------------------|--------------------------|-------------------|--------------|-----------|
| EL3828A12N    | 38 mm, 28 mm              | #12, #9               |                          |                   | 55 mm        | 119mm     |
| EL3425A12N    | 34 mm, 25 mm              |                       |                          |                   | 50 mm        | 119mm     |
| EL3625A12N    | 36 mm, 25 mm              | #11, #8               | 35M, 25 MILJONER EURO    |                   | 50 mm        | 116mm     |
| EL4028A12N    | 40 mm, 28 mm              |                       |                          |                   | 55 mm        | 123mm     |
| EL3830A12N    | 38 mm, 30 mm              |                       |                          |                   | 55 mm        | 130mm     |
| EL4030A12N    | 40 mm, 30 mm              |                       |                          |                   | 55 mm        | 134mm     |
| EL3422A12N    | 34 mm, 22 mm              |                       |                          |                   | 50 mm        | 117mm     |
| EL3825A12N    | 38 mm, 25 mm              | #12, #8               |                          |                   | 55 mm        | 118mm     |
| EL4025A12N    | 40 mm, 25 mm              |                       |                          |                   | 55 mm        | 122mm     |
| EL3622A12N    | 36 mm, 22 mm              | #11, #7               |                          |                   | 50 mm        | 114mm     |
| EL3420A12N    | 34 mm, 20 mm              |                       |                          |                   | 50 mm        | 115mm     |
| EL3620A12N    | 36 mm, 20 mm              | #11, #6               | 35M, 20 MILJONER EURO    |                   | 50 mm        | 112mm     |
| EL50T36A12N   | 50 mm, 36 mm              |                       |                          |                   | 70 mm        | 153mm     |
| EL43T36A12N   | 43 mm, 36 mm              | #14, #11              | 45M., 35M                |                   | 60 mm        | 148mm     |
| EL50T40A12N   | 50 mm, 40 mm              |                       |                          |                   | 70 mm        | 157mm     |
| EL50T38A12N   | 50 mm, 38 mm              |                       |                          |                   | 70 mm        | 154mm     |
| EL50T32A12N   | 50 mm, 32 mm              |                       |                          |                   | 70 mm        | 147mm     |
| EL50T34A12N   | 50 mm, 34 mm              |                       |                          |                   | 70 mm        | 156mm     |
| EL57T43TA12N  | 57 mm, 43 mm              | #18, #14              | 55M, 45M.                |                   | 80 mm        | 184mm     |

Table 1/4

| Katalognummer | Skendjup 1 (BD1) | Skendjup 2 (BD2) | Skenavstånd (BG) | Enhetsvikt | Antal i förpackningen | Certifieringar                                                                                  |
|---------------|------------------|------------------|------------------|------------|-----------------------|-------------------------------------------------------------------------------------------------|
| EL1210A12N    | 19mm             | 18mm             | 18mm             | 0.08 kg    | 285                   | DIBt, nVent LENTON EPD - Product Specific, Kontrollrådet, ITB, RISE                             |
| EL1614A12N    | 24mm             | 21mm             | 19mm             | 0.14 kg    | 150                   | DIBt, KOMO, nVent LENTON EPD - Product Specific, Kontrollrådet, ITB, RISE, Kontrollrådet, CARES |
| EL1612A12N    | 24mm             | 19mm             | 18mm             | 0.14 kg    | 150                   | KOMO, RISE, Kontrollrådet, CARES, ITB, Kontrollrådet, nVent LENTON EPD - Product Specific       |
| EL1412A12N    | 21mm             | 19mm             | 17mm             | 0.14 kg    | 150                   | KOMO, ITB, CARES, Kontrollrådet, nVent LENTON EPD - Product Specific, RISE, Kontrollrådet, DIBt |

| Katalognummer | Skendjup1<br>(BD1) | Skendjup2<br>(BD2) | Skenavstånd (BG) | Enhetsvikt | Antal i förpackningen | Certifieringar                                                                                  |
|---------------|--------------------|--------------------|------------------|------------|-----------------------|-------------------------------------------------------------------------------------------------|
| EL1410A12N    | 21mm               | 18mm               | 18mm             | 0.15 kg    | 150                   | nVent LENTON EPD - Product Specific, ITB, Kontrollrådet                                         |
| EL1610A12N    | 24mm               | 18mm               | 19mm             | 0.15 kg    | 150                   | ITB, nVent LENTON EPD - Product Specific, Kontrollrådet                                         |
| EL1814A12N    | 29mm               | 21mm               | 19mm             | 0.25 kg    | 70                    | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL1812A12N    | 29mm               | 19mm               | 18mm             | 0.25 kg    | 70                    | nVent LENTON EPD - Product Specific, ITB                                                        |
| EL1810A12N    | 29mm               | 18mm               | 19mm             | 0.25 kg    | 70                    | nVent LENTON EPD - Product Specific, ITB                                                        |
| EL1816A12N    | 29mm               | 24mm               | 18mm             | 0.25 kg    | 70                    | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL2012A12N    | 35mm               | 19mm               | 20mm             | 0.26 kg    | 70                    | nVent LENTON EPD - Product Specific, ITB, CARES, Kontrollrådet, KOMO, Kontrollrådet, RISE       |
| EL2014A12N    | 35mm               | 21mm               | 21mm             | 0.27 kg    | 70                    | ITB, CARES, RISE, Kontrollrådet, nVent LENTON EPD - Product Specific, Kontrollrådet, KOMO       |
| EL2018A12N    | 35mm               | 29mm               | 21mm             | 0.27 kg    | 70                    | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL2010A12N    | 35mm               | 18mm               | 21mm             | 0.27 kg    | 70                    | ITB, nVent LENTON EPD - Product Specific, Kontrollrådet                                         |
| EL2016A12N    | 35mm               | 24mm               | 21mm             | 0.27 kg    | 70                    | Kontrollrådet, DIBt, nVent LENTON EPD - Product Specific, ITB, Kontrollrådet, KOMO, RISE, CARES |
| EL2212A12N    | 37mm               | 19mm               | 21mm             | 0.34 kg    | 50                    | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL2216A12N    | 37mm               | 24mm               | 22mm             | 0.35 kg    | 50                    | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL2210A12N    | 37mm               | 18mm               | 22mm             | 0.35 kg    | 50                    | nVent LENTON EPD - Product Specific, ITB                                                        |
| EL2214A12N    | 37mm               | 21mm               | 22mm             | 0.35 kg    | 50                    | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL2218A12N    | 37mm               | 29mm               | 21mm             | 0.36 kg    | 50                    | ITB, nVent LENTON EPD - Product Specific                                                        |

Table 2/4

| Katalognummer | Skendjup<br>1 (BD1) | Skendjup<br>2 (BD2) | Skenavstånd<br>(BG) | Enhetsvikt | Antal i<br>förpackningen | Certifieringar                                                                                  |
|---------------|---------------------|---------------------|---------------------|------------|--------------------------|-------------------------------------------------------------------------------------------------|
| EL2220A12N    | 37mm                | 35mm                | 23mm                | 0.38 kg    | 50                       | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL2512A12N    | 40mm                | 19mm                | 22mm                | 0.43 kg    | 50                       | ITB, CARES, RISE, Kontrollrådet, nVent LENTON EPD - Product Specific, KOMO, Kontrollrådet       |
| EL2510A12N    | 40mm                | 18mm                | 23mm                | 0.44 kg    | 50                       | nVent LENTON EPD - Product Specific, Kontrollrådet                                              |
| EL2514A12N    | 40mm                | 21mm                | 22mm                | 0.44 kg    | 50                       | nVent LENTON EPD - Product Specific, Kontrollrådet, RISE, CARES, ITB, Kontrollrådet, KOMO       |
| EL2516A12N    | 40mm                | 24mm                | 22mm                | 0.45 kg    | 50                       | Kontrollrådet, ITB, CARES, KOMO, RISE, Kontrollrådet, nVent LENTON EPD - Product Specific       |
| EL2518A12N    | 40mm                | 29mm                | 21mm                | 0.47 kg    | 50                       | nVent LENTON EPD - Product Specific, ITB                                                        |
| EL2522A12N    | 40mm                | 37mm                | 23mm                | 0.49 kg    | 50                       | nVent LENTON EPD - Product Specific, ITB                                                        |
| EL2520A12N    | 40mm                | 35mm                | 23mm                | 0.5 kg     | 50                       | Kontrollrådet, CARES, DIBt, nVent LENTON EPD - Product Specific, RISE, Kontrollrådet, KOMO, ITB |
| EL2814A12N    | 42mm                | 21mm                | 23mm                | 0.61 kg    | 38                       | ITB, nVent LENTON EPD - Product Specific, KOMO                                                  |
| EL2816A12N    | 42mm                | 24mm                | 22mm                | 0.62 kg    | 38                       | nVent LENTON EPD - Product Specific, ITB, KOMO                                                  |
| EL2818A12N    | 42mm                | 29mm                | 22mm                | 0.65 kg    | 38                       | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL3016A12N    | 52mm                | 24mm                | 23mm                | 0.66 kg    | 34                       | nVent LENTON EPD - Product Specific                                                             |
| EL2825A12N    | 42mm                | 40mm                | 22mm                | 0.67 kg    | 38                       | nVent LENTON EPD - Product Specific, ITB, KOMO, DIBt                                            |
| EL3028A12N    | 52mm                | 42mm                | 23mm                | 0.68 kg    | 34                       | nVent LENTON EPD - Product Specific                                                             |
| EL2820A12N    | 42mm                | 35mm                | 24mm                | 0.69 kg    | 38                       | nVent LENTON EPD - Product Specific, ITB, KOMO                                                  |
| EL3018A12N    | 52mm                | 29mm                | 22mm                | 0.69 kg    | 34                       | nVent LENTON EPD - Product Specific                                                             |
| EL2822A12N    | 42mm                | 37mm                | 24mm                | 0.69 kg    | 38                       | ITB, nVent LENTON EPD - Product Specific                                                        |
| EL3025A12N    | 52mm                | 40mm                | 23mm                | 0.71 kg    | 34                       | nVent LENTON EPD - Product Specific                                                             |
| EL3020A12N    | 52mm                | 35mm                | 23mm                | 0.73 kg    | 34                       | nVent LENTON EPD - Product Specific                                                             |
| EL3022A12N    | 52mm                | 37mm                | 24mm                | 0.73 kg    | 34                       | nVent LENTON EPD - Product Specific                                                             |

Table 3/4

| Katalognummer | Skendjup 1 (BD1) | Skendjup 2 (BD2) | Skenavstånd (BG) | Enhetsvikt | Antal i förpackningen | Certifieringar                                                                            |
|---------------|------------------|------------------|------------------|------------|-----------------------|-------------------------------------------------------------------------------------------|
| EL3216A12N    | 45mm             | 24mm             | 23mm             | 0.81 kg    | 16                    | Kontrollrådet, CARES, Kontrollrådet, KOMO, ITB, RISE, nVent LENTON EPD - Product Specific |
| EL3218A12N    | 45mm             | 29mm             | 24mm             | 0.86 kg    | 16                    | nVent LENTON EPD - Product Specific, ITB                                                  |
| EL3228A12N    | 45mm             | 42mm             | 23mm             | 0.88 kg    | 16                    | KOMO, DIBt, nVent LENTON EPD - Product Specific, ITB                                      |
| EL4038A12N    | 57mm             | 53mm             | 23mm             | 1.47 kg    | 12                    | nVent LENTON EPD - Product Specific                                                       |
| EL3432A12N    | 55mm             | 45mm             | 23mm             | 1.24 kg    | 16                    | nVent LENTON EPD - Product Specific                                                       |
| EL3836A12N    | 53mm             | 52mm             | 23mm             | 1.51 kg    | 12                    | nVent LENTON EPD - Product Specific                                                       |
| EL3632A12N    | 52mm             | 45mm             | 23mm             | 1.15 kg    | 16                    | nVent LENTON EPD - Product Specific                                                       |
| EL4036A12N    | 57mm             | 52mm             | 23mm             | 1.5 kg     | 12                    | nVent LENTON EPD - Product Specific                                                       |
| EL3634A12N    | 52mm             | 55mm             | 23mm             | 1.23 kg    | 16                    | nVent LENTON EPD - Product Specific                                                       |
| EL3225A12N    | 45mm             | 40mm             | 24mm             | 0.91 kg    | 16                    | ITB, KOMO, RISE, CARES, Kontrollrådet, Kontrollrådet, nVent LENTON EPD - Product Specific |
| EL3428A12N    | 55mm             | 42mm             | 23mm             | 1.28 kg    | 16                    | nVent LENTON EPD - Product Specific                                                       |
| EL3230A12N    | 45mm             | 52mm             | 23mm             | 0.95 kg    | 16                    | nVent LENTON EPD - Product Specific                                                       |
| EL3832A12N    | 53mm             | 45mm             | 24mm             | 1.51 kg    | 12                    | nVent LENTON EPD - Product Specific                                                       |
| EL3220A12N    | 45mm             | 35mm             | 25mm             | 0.92 kg    | 16                    | CARES, RISE, Kontrollrådet, Kontrollrådet, nVent LENTON EPD - Product Specific, ITB, KOMO |
| EL3834A12N    | 53mm             | 55mm             | 24mm             | 1.62 kg    | 12                    | nVent LENTON EPD - Product Specific                                                       |
| EL4034A12N    | 57mm             | 55mm             | 24mm             | 1.61 kg    | 12                    | nVent LENTON EPD - Product Specific                                                       |
| EL3430A12N    | 55mm             | 52mm             | 24mm             | 1.37 kg    | 16                    | nVent LENTON EPD - Product Specific                                                       |
| EL4032A12N    | 57mm             | 45mm             | 24mm             | 1.5 kg     | 12                    | nVent LENTON EPD - Product Specific, Kontrollrådet, DIBt, CARES, ITB, RISE                |
| EL3222A12N    | 45mm             | 37mm             | 25mm             | 0.93 kg    | 16                    | ITB, nVent LENTON EPD - Product Specific                                                  |
| EL3628A12N    | 52mm             | 42mm             | 24mm             | 1.19 kg    | 16                    | nVent LENTON EPD - Product Specific                                                       |

Table 4/4

| Katalognummer | Skendjup 1 (BD1) | Skendjup 2 (BD2) | Skenavstånd (BG) | Enhetsvikt | Antal i förpackningen | Certifieringar                      |
|---------------|------------------|------------------|------------------|------------|-----------------------|-------------------------------------|
| EL3630A12N    | 52mm             | 52mm             | 24mm             | 1.28 kg    | 16                    | nVent LENTON EPD - Product Specific |

| Katalognummer | Skendjup 1 (BD1) | Skendjup 2 (BD2) | Skenavstånd (BG) | Enhetsvikt | Antal i förpackningen | Certifieringar                                                       |
|---------------|------------------|------------------|------------------|------------|-----------------------|----------------------------------------------------------------------|
| EL3828A12N    | 53mm             | 42mm             | 24mm             | 1.54 kg    | 12                    | nVent LENTON EPD - Product Specific                                  |
| EL3425A12N    | 55mm             | 40mm             | 24mm             | 1.31 kg    | 16                    | nVent LENTON EPD - Product Specific                                  |
| EL3625A12N    | 52mm             | 40mm             | 24mm             | 1.22 kg    | 16                    | nVent LENTON EPD - Product Specific                                  |
| EL4028A12N    | 57mm             | 42mm             | 24mm             | 1.54 kg    | 12                    | nVent LENTON EPD - Product Specific, ITB                             |
| EL3830A12N    | 53mm             | 52mm             | 25mm             | 1.67 kg    | 12                    | nVent LENTON EPD - Product Specific                                  |
| EL4030A12N    | 57mm             | 52mm             | 25mm             | 1.66 kg    | 12                    | nVent LENTON EPD - Product Specific                                  |
| EL3422A12N    | 55mm             | 37mm             | 25mm             | 1.32 kg    | 16                    | nVent LENTON EPD - Product Specific                                  |
| EL3825A12N    | 53mm             | 40mm             | 25mm             | 1.56 kg    | 12                    | nVent LENTON EPD - Product Specific                                  |
| EL4025A12N    | 57mm             | 40mm             | 25mm             | 1.56 kg    | 100                   | RISE, ITB, Kontrollrådet, CARES, nVent LENTON EPD - Product Specific |
| EL3622A12N    | 52mm             | 37mm             | 25mm             | 1.22 kg    | 16                    | nVent LENTON EPD - Product Specific                                  |
| EL3420A12N    | 55mm             | 35mm             | 25mm             | 1.31 kg    | 16                    | nVent LENTON EPD - Product Specific                                  |
| EL3620A12N    | 52mm             | 35mm             | 25mm             | 1.22 kg    | 16                    | nVent LENTON EPD - Product Specific                                  |
| EL50T36A12N   | 70mm             | 52mm             | 31mm             | 3.08 kg    | 1                     | nVent LENTON EPD - Product Specific                                  |
| EL43T36A12N   | 66mm             | 52mm             | 30mm             | 2.1 kg     | 10                    | nVent LENTON EPD - Product Specific                                  |
| EL50T40A12N   | 70mm             | 57mm             | 30mm             | 3.09 kg    | 8                     | CARES, nVent LENTON EPD - Product Specific                           |
| EL50T38A12N   | 70mm             | 53mm             | 31mm             | 3.06 kg    | 8                     | nVent LENTON EPD - Product Specific                                  |
| EL50T32A12N   | 70mm             | 45mm             | 32mm             | 3 kg       | 8                     | nVent LENTON EPD - Product Specific, CARES                           |
| EL50T34A12N   | 70mm             | 55mm             | 31mm             | 3.22 kg    | 8                     | nVent LENTON EPD - Product Specific                                  |
| EL57T43TA12N  | 83mm             | 66mm             | 35mm             | 4.87 kg    | 5                     | nVent LENTON EPD - Product Specific                                  |


**Utformad för att möta:**

AASHTO;ABNT NBR 8548:1984;ACI 318 typ 1 (125 % angivet utbyte);ACI 318 typ 2 (angiven draghållfasthet);ACI 349;ACI 359;AS3600

## YTTERLIGARE PRODUKTINFORMATION

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMS

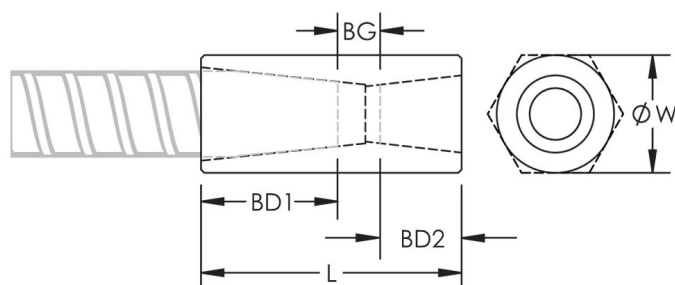

## VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på [www.nvent.com](http://www.nvent.com) och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vårt starka utbud av varumärken:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**