

Inbyggt rack 3 U, 84 HP

KATALOGNUMMER

10170-014

Lämplig för pågående vibrationer, stötar, höga temperaturer och hög luftfuktighet.

DESIGN

För mobila järnvägstillämpningar

Lämplig för pågående vibrationer, stötar, höga temperaturer och hög luftfuktighet

Passar för SNCF-underrack med 1, 2 eller 3 U (NF F61-005, CF 60-002)


Baksidan är utrustad för standardanslutningar; tvärstången kan specialkodas för SNCF-kodstiften

Tvärstag med integrerad kabelkanal

Flera rack kan staplas eller monteras i rader

Tillverkad med en svetsprocess, certifierad enligt en 15085 (CL2)

Rostfria svetsar passiverade för att förhindra korrosion

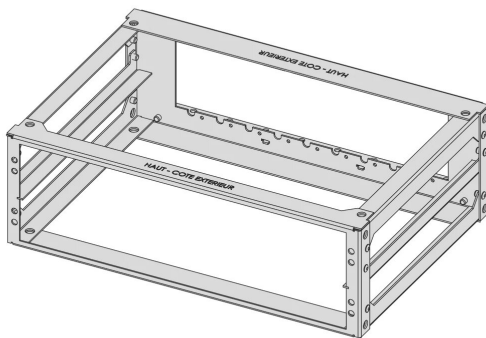

PRODUKTATTRIBUT

Produktfamilj: Inbyggt rack

Rackhöjd: 3U

Höjd: 156.7mm

Rackbredd: 84HP

Bredd: 496.4mm

Antal i förpackningen: 1

Uppfyller: SNCF NFF 61005; SNCF NFF 60002

Djup: 341.8mm

Rammaterial: Stål

Material: Rostfritt stål

Produkttyp: Rack

Statisk belastning: 25kg

Bruttovikt: 4.35kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE