

# Inserter/utdragare handtag typ IET, svart spak, grå knapp, topp; 10 stycken

## KATALOGNUMMER

**20817-654**


Kuverteringsmaskinens/utdragningshandtaget, typ IET i enlighet med IEEE 1101,10. Två av dessa handtag kan övervinna en enda spakkraft på 700 N (per par).

## DESIGN

Lämplig för in- och extraktionskrafter upp till 700 N (per par)

I enlighet med IEEE 1101,10 och IEC 60297-3-102

En mikrobrytare kan monteras

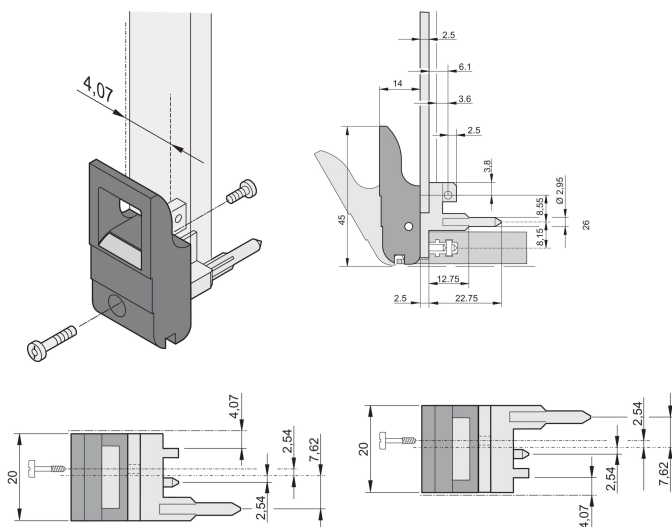

## PRODUKTATTRIBUT

Antal i förpackningen: 10

Handtagstyp: IET; Överst på framsidan; Nedre bakre i/O

Brandklassning: UL® 94V-0

Färg: Jet Black

Färgkod: RAL 9005

Uppfyller: EN 45545-2

Djup (D): 39.15mm

Höjd (H): 44.65mm

Material: Polykarbonat; Zinklegering

Produkttyp: Handtag

Typ: Införare/utdragare, standard

Bredd (W): 19.8mm

Fungerar med: Frontpaneler

Bruttovikt: 0.231kg


\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail

price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## YTTERLIGARE PRODUKTINFORMATION

Vänligen beställ kodpinnar och mikrobrytare separat.

## DIAGRAMS

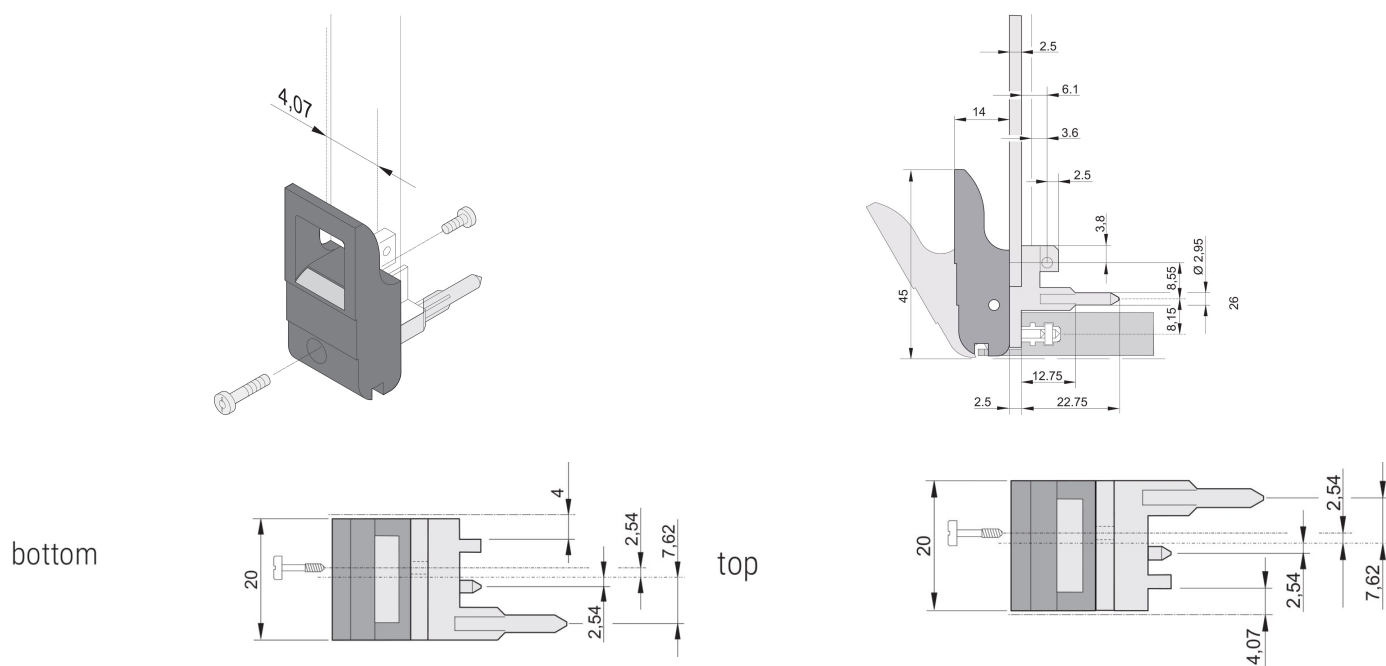

## VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på [www.nvent.com](http://www.nvent.com) och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Vårt starka utbud av varumärken:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**