


Frontpanelsats, oskärmad, Bottengångjärn, 3 U, 84 HP, 2,5 mm, Al, anodiserad

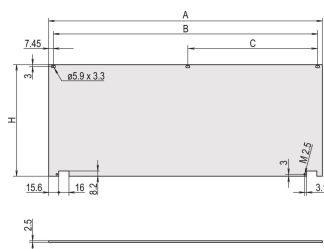

KATALOGNUMMER

20838-273

Oskärmad frontpanel med gångjärn i botten.

DESIGN

Frontpanelen kan öppnas i 135 graders öppningsvinkel (ej RatiopacPRO)

Möjliggör montering på horisontella skenor



PRODUKTATTRIBUT

Rackhöjd: 3U

Tillbehörstyp: Frontpanel

Rackbredd: 84HP

Antal i förpackningen: 1

Montage: Gångjärnsförsedd, underdel

Främre finish: Anodiserad

Bakre finish: Ledande

Behandlade kanter: Nej

Uppfyller: IEC 60297-3-101; IEEE 1101.1/10

Djup (D): 2.5mm

EMC-skydd: Nej

Yta: Anodiserad

Höjd (H): 128.4mm

Material: Aluminium

Produkttyp: Frontpanel

Typ: Frontpanel utan handtag

Bredd (W): 426.4mm

The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

Frontpanelen kan tas bort i öppet läge (> 135 grader).

Technical drawing of a rectangular plate with the following dimensions and features:

- Overall width: A
- Overall height: H
- Top edge features:
 - Left corner: 7.45 (horizontal distance from left edge to start of feature), 3 (vertical distance from top edge to start of feature).
 - Feature: $\varnothing 5.9 \times 3.3$ (hole diameter and depth).
 - Right corner: C (horizontal distance from right edge to start of feature), 3 (vertical distance from top edge to start of feature).
- Bottom edge features:
 - Left corner: 15.6 (horizontal distance from left edge to start of feature), 16 (horizontal distance from start of feature to end of feature), 8.2 (vertical distance from bottom edge to end of feature).
 - Feature: $M 2.5$ (threaded hole).
 - Right corner: 3 (horizontal distance from right edge to start of feature), 3.1 (vertical distance from bottom edge to start of feature).
- Bottom edge dimension: 2.5 (horizontal distance from left edge to start of feature).

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Straubenhardt, Germany
 +49.7082.794.0
 Betschdorf, France
 +33.3.88.90.64.90
 Warsaw, Poland
 +48.22.209.98.35
 Assago, Italy
 +39.02.932.7141
 Chat with us:
nvent.com/schroff

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE